


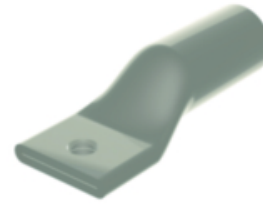

# Compression Terminal

By Burndy  
Catalog # YA30A7

AL Terminal, AL9CU, Internal Chamfer, Tin Plated, Prefilled PENETROX™ A13, End Cap, UL/CSA, 90°C, Up to 35kV, Color Code, Die Index.



## Application

Wire Termination

## General

Color Code	Blue
Connector Type	DUAL RATED
Die Index	470
Feature - Barrel Style	Chamfered
Feature - Barrel Type	Standard
Finish Type	Tin-Plated
Material	ALUMINUM
Physical Attribute - Number of Holes	1
Physical Attribute - Tongue Type	Standard
Plated	Y
Plating Type	Tin - Electro Plated
Temperature Rating	194
Trade Name	HYLUG™
UPC	781810033579
UPC 12 Digit	7818100335799

## Dimensions

Dimension - B Length fraction	1-7/16 in
Dimension - B Length inch	1.44 in
Dimension - Bolt Hole Size inch	0.27 in
Dimension - Bolt Size fraction	1/4
Dimension - Bolt Size inch	0.25
Dimension - D inch	1.37 in
Dimension - Hole Size fraction	1/4
Dimension - Hole Size inch	0.27
Dimension - Hole Size mm	6.9 mm
Dimension - Inside Diameter inch	0.65 in
Dimension - L Length Overall mm	99 mm
Dimension - Length Overall inch	3.90 in
Dimension - N inch	0.63 in
Dimension - Outside Diameter inch	1.01 in
Dimension - Pad Width inch	1.38 in
Dimension - Stud Size fraction	1/4
Dimension - Thread Size	1/4 in
Dimension - Z inch	0.74 in

## Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

## Conductor Related

Conductor - AL Str Size	300 KCMIL
Conductor - AL Str Size Range	300 kcmil
Conductor - Copper Str Size	300 KCMIL
Conductor - Copper Str Size Range	300 kcmil
Conductor - Material	ALUMINUM / COPPER
Conductor Size	300 KCMIL
Conductor Type	CODE
Wire Size	300 KCMIL

## Certifications and Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
Standards - Industry Standards Met	UL 486A-486B
Standards - RoHS Compliance Status	CM
UL Listed	Yes

## Logistics

Carton Quantity	5
Minimum Pack Quantity	5

## Product Assets

[Customer Notices - Prop 65 Notice](#)  
[Installation Manuals - Aluminum Installation Instructions](#)  
[Sales Drawings - SD208046](#)

Dimension - Z Inch 0.74 in  
Physical Attribute - Tongue Straight  
Angle

---



**A proud member of the Hubbell Family.**

©2023 Hubbell Incorporated. All rights reserved.  
BRDY-YA30A7-SPEC-EN | REV 8/2023