




# YA31L2TC3890, Compression Terminal, 350 kcmil Cu, 2-Hole, 3/8" Stud, 1" Spacing, Standard Barrel, 90 Degree

By Burndy  
Catalog # YA31L2TC3890

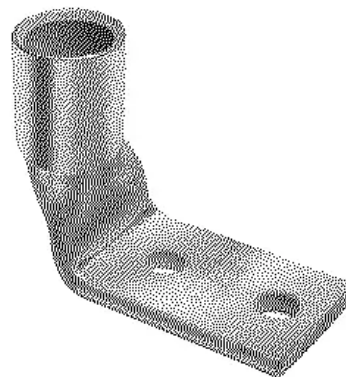

Copper Compression Lug, 2 Hole w/ Inspection Window, 350 kcmil, 3/8" Stud, 1" Stud Hole Spacing, Short Barrel, Tin - Electro Plated, 90 degree.

## Features

- Barrel designed with internal chamfer at wire entry for smooth insertion of wire, preventing possible damage of the strands
- Standard barrel length is recommended for installations with limited space availability
- Electro-tin plated unless otherwise specified to reduce galvanic corrosion (bimetallic) and resist corrosive elements
- Connectors are clearly marked with stamping and barrel color coding
- 2-Hole design prevents rotation

## Application

Wire Termination

## General

Catalog Number	YA31L2TC3890
Color Code	Red
Connector Type	STANDARD BARREL
Die Index	18
Feature - Barrel Style	<ul style="list-style-type: none"><li>• Chamfered</li><li>• Skived</li></ul>
Feature - Barrel Type	Standard
Finish Type	Tin-Plated
Material	COPPER
Physical Attribute - Number of Holes	2
Physical Attribute - Tongue Type	Standard
Plated	Y
Plating Type	Tin - Electro Plated
Trade Name	HYLUG™
Type	Standard Barrel, Tin Plated
UPC	781810019436
UPC 12 Digit	7818100194366

## Dimensions

Dimension - B Length fraction	1-1/16 in
Dimension - B Length inch	1.06 in

Dimension - Bolt Hole Size inch	0.39 in
Dimension - Bolt Size fraction	3/8
Dimension - Bolt Size inch	0.38
Dimension - Height inch	1.98 in
Dimension - Hole Size fraction	3/8
Dimension - Hole Size inch	0.41
Dimension - Hole Size mm	10.4 mm
Dimension - L Length Overall mm	61 mm
Dimension - Length Overall inch	2.41 in
Dimension - N inch	0.41 in
Dimension - Outside Diameter inch	0.88 in
Dimension - Pad Width inch	1.29 in
Dimension - Strip Length inch	1-3/16
Dimension - Stud Size fraction	3/8
Dimension - Stud Size inch	3/8
Dimension - Z (inch)	0.42 in
Physical Attribute - Tongue Angle	90 Degree

## Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

## Conductor Related

Conductor - Copper DLO Size Range	N/A
Conductor - Copper Str Navy Size	350 (91) Navy
Conductor - Copper Str Size	350 KCMIL
Conductor - Copper Str Size Range	350 kcmil
Conductor - Material	COPPER
Conductor Size	350 KCMIL
Conductor Type	CODE

## Certifications And Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
Standards - Industry Standards Met	UL 486A-486B
Standards - RoHS Compliance Status	CM
UL Listed	Yes

## Logistics

Carton Quantity	10
Minimum Pack Quantity	10
Pallet Quantity	4640

## Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - se209512-27](#)
- [Specifications - YA31L2TC3890](#)
- [Video - HYDENT Compression Terminal Overview Video](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved  
BRDY-YA31L2TC3890-SPEC-EN | REV 10/2024