


# YA322NNT, Compression Terminal, 400 kcmil CU, 2-Hole, 1/2" Stud, 1-3/4" Spacing, Long Barrel, Narrow Tongue

By Burndy  
Catalog # YA322NNT

400 kcmil CU, Two Hole, 1/2 Stud Size, 1-3/4 Hole Spacing, Long Barrel, Narrow Tongue Internal Chamfer, Tin Plated, UL/CSA, 90°C, Up to 35kV, Blue Color Code, 19 Die Index.

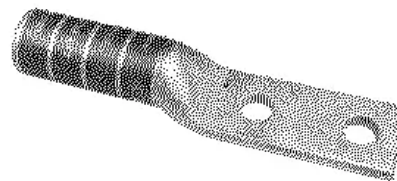

## Features

- Barrel designed with internal chamfer at wire entry for smooth insertion of wire, preventing possible damage of the strands
- Long barrel length allows for an increased number of crimps increasing the mechanical strength of the connection
- Electro-tin plated unless otherwise specified to reduce galvanic corrosion (bimetallic) and resist corrosive elements
- Connectors are clearly marked with stamping and barrel color coding
- 2-Hole design prevents rotation

## Application

Wire Termination

## General

Catalog Number	YA322NNT
Color Code	Blue
Connector Type	LONG BARREL
Die Index	19
Feature - Barrel Style	Chamfered
Finish Type	Tin-Plated
Material	COPPER
Physical Attribute - Number of Holes	2
Plated	Y
Plating Type	Tin
Trade Name	HYLUG™
UPC	781810672792

## Dimensions

Dimension - B Length fraction	2-3/25 in
Dimension - B Length inch	2.12 in
Dimension - Bolt Hole Size inch	0.56 in
Dimension - Bolt Size fraction	1/2
Dimension - Bolt Size inch	0.5
Dimension - Hole Size fraction	1/2
Dimension - Hole Size inch	0.56
Dimension - Hole Size mm	14 mm

Dimension - L Length Overall mm	148 mm
Dimension - Length Overall inch	5.85 in
Dimension - Outside Diameter inch	0.95 in
Dimension - Pad Width inch	0.96 in
Dimension - Strip Length inch	2-3/16 in
Dimension - Stud Size fraction	1/2
Dimension - Stud Size inch	1/2 in
Physical Attribute - Tongue Angle	Straight

## Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

## Conductor Related

Conductor - Copper DLO Size Range	N/A
Conductor - Copper Str Navy Size	400 (127)
Conductor - Copper Str Size	400 KCMIL
Conductor - Copper Str Size Range	400 kcmil
Conductor - Material	COPPER
Conductor Size	400 KCMIL
Conductor Type	CODE

## Certifications And Compliance

Certification - CSA Approved	Yes
Industry Standard(s)	UL 486A-486B
Standards - RoHS Compliance Status	CM
UL Listed	Yes

## Logistics

Carton Quantity	50
Minimum Pack Quantity	1

Pallet Quantity

5550

[Customer Notices - Prop 65 Notice](#)

[Installation Manuals - Copper Code Long Terminals Tooling and Installation Instructions](#)

[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)

[Sales Drawings - 50046237](#)

[Specifications - YA322NNT](#)

[Video - HYDENT Compression Terminal Overview Video](#)

## Product Assets

[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)

[Catalogs - BURNDY Master Catalog - Section C - Compression Connections](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved  
BRDY-YA322NNT-SPEC-EN | REV 10/2024