


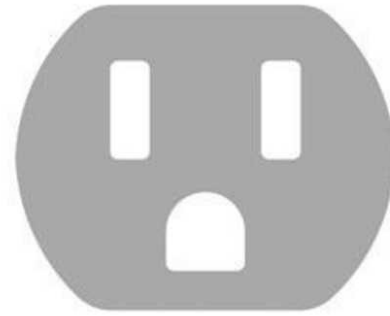

YA34A3N131T12E, 500 kcmil, Aluminum, 1 Hole, 1/2 Stud, AL9CU, Narrow Tongue

By Burndy
Catalog # [YA34A3N131T12E](#)

AL Terminal, AL9CU, Internal Chamfer, Tin Plated, Prefilled
PENETROX™ A13, End Cap, UL/CSA, 90°C, Up to 35kV, Color
Code, Die Index.



Oh No!
IMAGE COMING SOON

Application

Wire Termination

General

Color Code	Pink
Connector Type	DUAL RATED
Die Index	300
EU RoHS Indicator	Yes
Finish Type	Tin-Plated
Material	ALUMINUM
Sub Brand	TERMINALS, HYLUG
Trade Name	HYLUG™
Type	YA-E
UPC	781810290279

Dimensions

Dimension - Bolt Size fraction	1/2
Dimension - Bolt Size inch	0.5
Dimension - Hole Size fraction	1/2
Dimension - Hole Size inch	0.56
Dimension - Hole Size mm	14 mm
Dimension - Stud Size fraction	1/2
Physical Attribute - Tongue Angle	Straight

Electrical Ratings

Voltage Rating	35 kV
----------------	-------

Conductor Related

Conductor - AL Str Size	500 KCMIL
Conductor - Copper Str Size	500 KCMIL
Conductor - Copper Str Size Range	500 kcmil
Conductor - Material	ALUMINUM / COPPER
Conductor Size	500 KCMIL
Conductor Type	CODE
Wire Size	500 KCMIL

Certifications And Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Industry Standard(s)	UL 486A-486B
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	10
Minimum Pack Quantity	1
Pallet Quantity	4640

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - SD214515-01](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY-YA34A3N131T12E-SPEC-EN | REV 5/2024