




YA34TC12FXB, Compression Terminal, 350 kcmil G,H,I,K,M, 373 DLO, Cu, 1-Hole, 1/2" Stud, Long Barrel

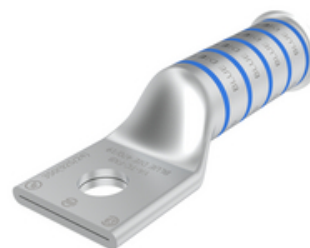

By Burndy
Catalog # [YA34TC12FXB](#)

350 kcmil G,H,I,K,M,373 DLO CU, One Hole, 1/2 Stud Size, Long Barrel, Bell End, Tin Plated, UL/CSA, 90°C, Up to 35kV, Blue Color Code, 19 Die Index.

Features

- Barrel designed with internal chamfer at wire entry for smooth insertion of wire, preventing possible damage of the strands
- Long barrel length allows for an increased number of crimps increasing the mechanical strength of the connection
- Electro-tin plated unless otherwise specified to reduce galvanic corrosion (bimetallic) and resist corrosive elements
- Connectors are clearly marked with stamping and barrel color

Application

Wire Termination

General

Catalog Number	YA34TC12FXB
Color Code	Blue
Connector Type	LONG BARREL
Die Index	19
EU RoHS Indicator	Yes
Feature - Barrel Style	Belled
Feature - Barrel Type	Long
Finish Type	Tin-Plated
Material	COPPER
Physical Attribute - Number of Holes	1
Physical Attribute - Tongue Type	Standard
Plated	Y
Plating Type	Tin - Electro Plated
Sub Brand	HYLUG
Trade Name	HYLUG™
Type	Long Barrel, Tin Plated
UPC	781810039885
UPC 12 Digit	7818100398855

Dimensions

Dimension - B Length fraction	2-1/2 in
Dimension - B Length inch	2.48 in
Dimension - Bolt Hole Size inch	0.52 in
Dimension - Bolt Size fraction	1/2
Dimension - Bolt Size inch	0.5
Dimension - Hole Size fraction	1/2
Dimension - Hole Size inch	0.56
Dimension - Hole Size mm	14 mm
Dimension - L Length Overall mm	115 mm
Dimension - Length Overall inch	4.54 in
Dimension - N inch	0.62 in
Dimension - Outside Diameter inch	1.06 in
Dimension - Pad Width inch	1.55 in
Dimension - Strip Length inch	2-9/16
Dimension - Stud Size fraction	1/2
Dimension - Stud Size inch	1/2
Dimension - Z (inch)	0.64 in
Physical Attribute - Tongue Angle	Straight

Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

Conductor Related

Conductor - Copper DLO Size	373 KCMIL
Conductor - Copper DLO Size	373 kcmil
Range	
Conductor - Copper Flex G Size	350 KCMIL
Conductor - Copper Flex G Size	350 kcmil
Range	
Conductor - Copper Flex H Size	350 KCMIL
Conductor - Copper Flex H Size	350 kcmil
Range	
Conductor - Copper Flex I Size	350 KCMIL
Conductor - Copper Flex I Size	350 kcmil
Range	
Conductor - Copper Flex K Size	350 KCMIL
Conductor - Copper Flex K Size	350 kcmil
Range	
Conductor - Copper Flex M Size	350 KCMIL
Conductor - Copper Flex M Size	373.7
Size Range	
Conductor - Copper Str Size	350 KCMIL
Conductor - Copper Str Size	350 kcmil
Range	
Conductor - Material	COPPER
Conductor Size	350 KCMIL
Conductor Type	FLEX
Wire Size	350 KCMIL

Certifications And Compliance

Buy American Compliant	Yes
Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
Standards - Industry Standards Met	UL 486A-486B
Standards - RoHS Compliance	CM
Status	
UL Listed	Yes

Logistics

Carton Quantity	25
Minimum Pack Quantity	1
Pallet Quantity	3700

Product Assets

[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Catalogs - BURNDY Master Catalog - Section C - Compression Connections](#)
[Customer Notices - Prop 65 Notice](#)
[Installation Manuals - Copper Flex Long Terminals Tooling and Installation Instructions](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Sales Drawings - SE208075](#)
[Video - HYDENT Compression Terminal Overview Video](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
BRDY-YA34TC12FXB-SPEC-EN | REV 8/2024