




## YA362TC38, Compression Terminal, 600 kcmil Cu, 2-Hole, 3/8" Stud, 1" Spacing, Long Barrel

By Burndy

Catalog # [YA362TC38](#)

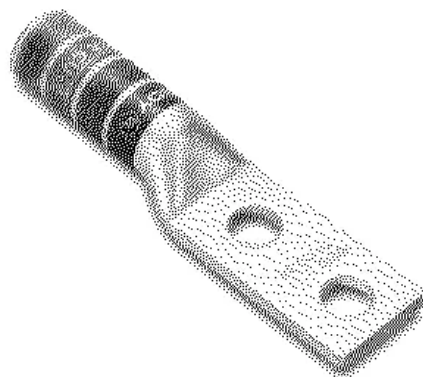

600 kcmil CU, Two Hole, 3/8 Stud Size, 1 Hole Spacing, Long Barrel Internal Chamfer, Tin Plated, UL/CSA, 90°C, Up to 35kV, Green Color Code, 22 or 472 Die Index.

### Features

- Barrel designed with internal chamfer at wire entry for smooth insertion of wire, preventing possible damage of the strands
- Long barrel length allows for an increased number of crimps increasing the mechanical strength of the connection
- Electro-tin plated unless otherwise specified to reduce galvanic corrosion (bimetallic) and resist corrosive elements
- Connectors are clearly marked with stamping and barrel color coding
- 2-Hole design prevents rotation

### Application

Wire Termination

### General

Catalog Number	YA362TC38
Color Code	Green
Connector Type	LONG BARREL
Die Index	22
EU RoHS Indicator	Yes
Feature - Barrel Style	Chamfered
Feature - Barrel Type	Long
Finish Type	Tin-Plated
Material	COPPER
Physical Attribute - Number of Holes	2
Physical Attribute - Tongue Type	Standard
Plated	Y
Plating Type	Tin - Electro Plated
Sub Brand	HYLUG
Trade Name	HYLUG™
Type	Long Barrel, Tin Plated
UPC	781810021132
UPC 12 Digit	7818100211322

### Dimensions

Dimension - B Length fraction	2-11/16 in
Dimension - B Length inch	2.69 in

Dimension - Bolt Hole Size inch	0.39 in
Dimension - Bolt Size fraction	3/8
Dimension - Bolt Size inch	0.38
Dimension - Hole Size fraction	3/8
Dimension - Hole Size inch	0.41
Dimension - Hole Size mm	10.4 mm
Dimension - L Length Overall mm	142 mm
Dimension - Length Overall inch	5.59 in
Dimension - N inch	0.50 in
Dimension - Outside Diameter inch	1.19 in
Dimension - Pad Width inch	1.74 in
Dimension - Strip Length inch	2-3/4
Dimension - Stud Size fraction	3/8
Dimension - Stud Size inch	3/8
Dimension - Z (inch)	0.53 in
Physical Attribute - Tongue Angle	Straight

### Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

### Conductor Related

Conductor - Copper DLO Size Range	N/A
Conductor - Copper Str Size	600 KCMIL
Conductor - Copper Str Size Range	600 kcmil
Conductor - Material	COPPER
Conductor Size	600 KCMIL
Conductor Type	CODE

### Certifications And Compliance

Buy American Compliant	Yes
Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No

Industry Standard(s)	UL 486A-486B
Standards - Industry Standards Met	UL 486A-486B
Standards - RoHS Compliance Status	CM
UL Listed	Yes

### Logistics

Carton Quantity	25
Minimum Pack Quantity	1
Pallet Quantity	2400

### Product Assets

- [Catalogs - BURNDY Master Catalog - Section C - Compression Connections](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Installation Manuals - Copper Code Long Terminals Tooling and Installation Instructions](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - SE..208777-01](#)
- [Specifications - YA362TC38](#)
- [Video - HYDENT Compression Terminal Overview Video](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved  
BRDY-YA362TC38-SPEC-EN | REV 10/2024