


# YA392ENNT, Compression Terminal, 750 kcmil Cu, 2-Hole, 1/2" Stud, 1-3/4" Spacing, Long Barrel, Narrow Tongue

By Burndy  
Catalog # [YA392ENNT](#)

750 kcmil CU, Two Hole, 1/2 Stud Size, 1-3/4 Hole Spacing, Long Barrel Internal Chamfer, Tin Plated, UL/CSA, 90°C, Up to 35kV, Black Color Code, 24 Die Index.

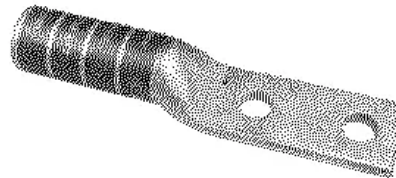

## Features

- Barrel designed with internal chamfer at wire entry for smooth insertion of wire, preventing possible damage of the strands
- Long barrel length allows for an increased number of crimps increasing the mechanical strength of the connection
- Electro-tin plated unless otherwise specified to reduce galvanic corrosion (bimetallic) and resist corrosive elements
- Connectors are clearly marked with stamping and barrel color coding
- 2-Hole design prevents rotation

## Application

Wire Termination

## General

Catalog Number	YA392ENNT
Color Code	Black
Connector Type	LONG BARREL
Die Index	24
Feature - Barrel Style	Chamfered
Finish Type	Tin-Plated
Material	COPPER
Physical Attribute - Number of Holes	2
Plated	Y
Plating Type	Tin
Trade Name	HYLUG™
UPC	781810527399

## Dimensions

Dimension - B Length fraction	2-7/8 in
Dimension - B Length inch	2.88 in
Dimension - Bolt Hole Size inch	0.56 in
Dimension - Bolt Size fraction	1/2
Dimension - Bolt Size inch	0.5
Dimension - Hole Size fraction	1/2
Dimension - Hole Size inch	0.56
Dimension - Hole Size mm	14 mm

Dimension - L Length Overall mm	174 mm
Dimension - Length Overall inch	6.87 in
Dimension - Outside Diameter inch	1.30 in
Dimension - Pad Width inch	1.30 in
Dimension - Strip Length inch	2-15/16
Dimension - Stud Size fraction	1/2
Dimension - Stud Size inch	1/2
Physical Attribute - Tongue Angle	Straight

## Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

## Conductor Related

Conductor - Copper DLO Size Range	N/A
Conductor - Copper Str Size Range	750 KCMIL
Conductor - Copper Str Size	750 kcmil
Conductor - Material	COPPER
Conductor Size	750 KCMIL
Conductor Type	CODE

## Certifications And Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
Standards - RoHS Compliance Status	CM
UL Listed	Yes

## Logistics

Carton Quantity	6
-----------------	---

Minimum Pack Quantity 6  
Pallet Quantity 2352

### Product Assets

3D Models - YA392ENNT\_MODEL-IGES  
3D Models - YA392ENNT\_MODEL-STEP  
3D Models - YA392ENNT\_MODEL-PDF  
Catalogs - BURNDY Master Catalog - Section C - Compression Connections

Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog  
Customer Notices - Prop 65 Notice  
Installation Manuals - Copper Code Long Terminals Tooling and Installation Instructions  
Interactive Catalog - BURNDY Full-Line Digital Catalog  
Sales Drawings - sd031189-05  
Specifications - YA392ENNT  
Video - HYDENT Compression Terminal Overview Video



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved  
BRDY-YA392ENNT-SPEC-EN | REV 10/2024