



YA402ENNTFX, 2-hole Long Barrel Connector, No Window, Narrow Tongue


By Burndy
Catalog # [YA402ENNTFX](#)

650 kcmil G, 646 DLO CU, Two Hole, 1/2 Stud Size, 1-3/4 Hole Spacing, Long Barrel, No Window, Narrow Tongue, Internal Chamfer, Tin Plated, UL/CSA, 90°C, Up to 35kV, Black Color Code, 24 Die Index

Features

- No inspection window is ideal for more corrosive environments as the barrel transition is not open
- Barrel is designed with a "chamfer" end opening at the wire entry to ensure smooth insertion of wire
- Long barrel allows for an increased number of crimps which will increase the mechanical strength of the connection
- Two hole tongue/tang is recommended when space permits as the 2-hole feature minimizes the terminations from loosening or rotatng under vibration, movement, or heat cycling

General

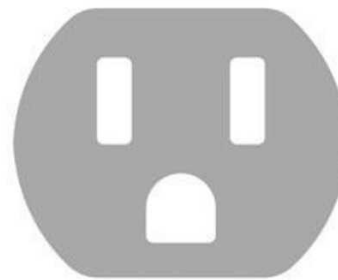

Oh No!
IMAGE COMING SOON

Catalog Number	YA402ENNTFX
Type	Cable to Flat
UPC	621945619074

Logistics

Carton Quantity	25
Pallet Quantity	1800

Product Assets

[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Sales Drawings - 50111162](#)
[Specifications - YA402ENNTFX](#)
[Video - HYDENT Compression Terminal Overview Video](#)