




# Nylon Fork Terminal For 12 - 10 AWG

By Burndy  
Catalog # [YAE10N82FBOX](#)

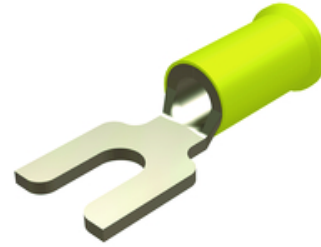

Fork Tongue Terminals, 12 AWG - 10 AWG, 8-10, 1.02 in L, .37 in W.

## Application

Power Connector

## General

|                                  |                      |
|----------------------------------|----------------------|
| Color Code                       | Yellow               |
| Connector Type                   | Fork Terminal        |
| Construction Material - Main     | Copper               |
| EU RoHS Indicator                | Contact Manufacturer |
| Feature - Barrel Type            | Standard             |
| Finish Type                      | Tin-Plated           |
| Insulation                       | Y                    |
| Insulation Type                  | Nylon                |
| Material                         | Copper               |
| Physical Attribute - Tongue Type | Fork Terminal        |
| Plated                           | Y                    |
| Plating Type                     | Electro Tin          |
| Sub Brand                        | INSULUG              |
| Temperature Rating               | 105° C               |
| Trade Name                       | INSULUG™             |
| Type                             | YAE-NF               |
| UPC                              | 781810524497         |
| UPC 12 Digit                     | 7818105244977        |

## Dimensions

|                                 |          |
|---------------------------------|----------|
| Dimension - Bolt Size fraction  | #8 - #10 |
| Dimension - L Length Overall mm | 26 mm    |
| Dimension - Length Overall inch | 1.02 in  |
| Dimension - Pad Width inch      | 0.37 in  |
| Dimension - Strip Length inch   | 3/8 in   |
| Dimension - Stud Size inch      | #8 - #10 |
| Dimension - Z inch              | 0.29 in  |

## Electrical Ratings

|                   |       |
|-------------------|-------|
| Voltage - Maximum | 600 V |
| Voltage Rating    | 600 V |

## Conductor Related

|                                   |                 |
|-----------------------------------|-----------------|
| Conductor - Copper Str Size Range | 12 AWG - 10 AWG |
| Conductor Size                    | 12 - 10 AWG     |
| Conductor Type                    | CU C Str-Size   |

## Certifications and Compliance

|                                    |    |
|------------------------------------|----|
| Certification - CSA Approved       | No |
| Certification - ETL                | No |
| Certification - UL Recognized      | No |
| Certification - cULus              | No |
| Standards - RoHS Compliance Status | CM |
| UL Listed                          | No |

## Logistics

|                       |     |
|-----------------------|-----|
| Carton Quantity       | 100 |
| Minimum Pack Quantity | 1   |

## Product Assets

[Catalogs - Full Line BURNDY Catalog](#)  
[Sales Drawings - 50094173](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
BRDY-YAE10N82FBOX-SPEC-EN | REV 8/2023