




YAE18N60FBOX, Nylon Fork Terminal For 22 - 18 AWG

By Burndy
Catalog # [YAE18N60FBOX](#)

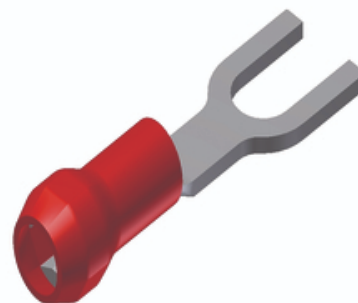

Nylon Fork Terminal For 22 - 18 AWG.

Features

- Multi-finger insulation grip provides superior insulation holding characteristics, especially on EPR and other elastic-type insulations
- Brazed seam provides a stronger, more durable termination
- Manufactured of pure electrolytic copper for maximum conductivity, low resistance, and ductility for excellent crimp forming properties
- Deep V groove, inner barrel serrations for optimum conductivity, reliability and holding power
- Smooth funnel entry for easy wire insertion

Application

Power Connector

General

Catalog Number	YAE18N60FBOX
Color Code	Red
Connector Type	Fork Terminal
Feature - Barrel Style	Shrouded
Insulation	Y
Insulation Type	Nylon
Material	Copper
Physical Attribute - Number of Holes	1
Physical Attribute - Tongue Type	Fork
Plated	Y
Plating Type	Tin - Electro Plated
Trade Name	INSULUG™
UPC	781810023198
UPC 12 Digit	7818100231988

Dimensions

Cable Insulation Diameter Maximum	0.125 in
Dimension - Bolt Size fraction	#4
Dimension - Hole Size fraction	3/25
Dimension - Hole Size inch	0.12 in
Dimension - L Length Overall mm	23 mm
Dimension - Length Overall inch	0.92 in
Dimension - N inch	0.25 in
Dimension - Pad Width inch	0.21 in
Dimension - Strip Length inch	3/16 in
Dimension - Stud Size inch	#4
Dimension - Z (inch)	0.24 in

Electrical Ratings

Voltage - Maximum	600 V
-------------------	-------

Conductor Related

Conductor - Copper Str Aircraft Size	AN 22;AN 20;AN 18;AN 16
Conductor - Copper Str Size	20;18;16
Conductor - Copper Str Size Range	20 AWG - 16 AWG
Conductor Size	22 - 18 AWG
Conductor Type	<ul style="list-style-type: none">• CU C Solid-Size• CU C Str-Size

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	<ul style="list-style-type: none">• UL486• Military Specified (Mil-Spec)
Standards - Industry Standards Met	UL486;Military Specified (Mil-Spec)
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	1200
Minimum Pack Quantity	100
Pallet Quantity	99999

Product Assets

[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Catalogs - BURNDY Master Catalog - Section B - Small Compression](#)
[Customer Notices - Prop 65 Notice](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Sales Drawings - 50094173](#)
[Specifications - YAE18N60FBOX](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
BRDY-YAE18N60FBOX-SPEC-EN | REV 8/2024