




**YAV26L2ENT14FX, Cu**  
**Compression, 2-Hole, 1/4" Stud,**  
**5/8" Spacing, Extra Narrow Tongue,**  
**Standard Barrel, 2/0 Flex**

By Burndy  
Catalog # [YAV26L2ENT14FX](#)

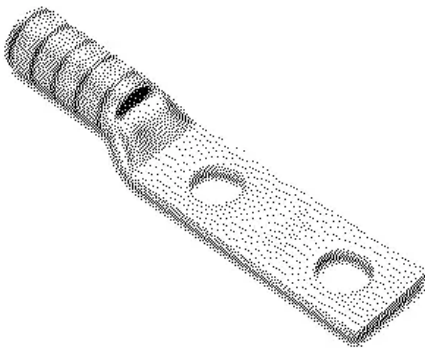

Uninsulated Copper compression lug, 2 Hole, 35kV, Tin plated,  
1/4" Stud hole size.

**Features**

- Electro-tin plated unless otherwise specified to reduce galvanic corrosion (bimetallic) and resist corrosive elements
- Connectors are clearly marked with stamping and barrel color coding
- For applications greater than 2000 Volts consult cable manufacturer for voltage stress relief instructions

**Application**

Wire Termination

**General**

|                                      |                             |
|--------------------------------------|-----------------------------|
| Catalog Number                       | YAV26L2ENT14FX              |
| Color Code                           | Black                       |
| Connector Type                       | STANDARD BARREL             |
| Die Index                            | 13                          |
| EU RoHS Indicator                    | Contact Manufacturer        |
| Feature - Barrel Style               | Chamfered                   |
| Feature - Barrel Type                | Standard                    |
| Finish Type                          | Tin-Plated                  |
| Material                             | COPPER                      |
| Physical Attribute - Number of Holes | 2                           |
| Plated                               | Y                           |
| Plating Type                         | Tin - Electro Plated        |
| Trade Name                           | HYLUG™                      |
| Type                                 | Standard Barrel, Tin Plated |
| UPC                                  | 621945436442                |
| UPC 14 Digit GTIN                    | 00621945436442              |

**Dimensions**

|                                 |          |
|---------------------------------|----------|
| Dimension - B Length fraction   | 13/16 in |
| Dimension - B Length inch       | 0.81     |
| Dimension - Bolt Hole Size inch | 0.27 in  |
| Dimension - Bolt Size fraction  | 1/4      |
| Dimension - Bolt Size inch      | 0.25     |
| Dimension - D inch              | 1.28 in  |
| Dimension - Height mm           | 0 mm     |
| Dimension - Hole Size fraction  | 1/4      |
| Dimension - Hole Size inch      | 0.27     |

|                                   |          |
|-----------------------------------|----------|
| Dimension - Hole Size mm          | 6.9 mm   |
| Dimension - L Length Overall mm   | 65 mm    |
| Dimension - Length Overall inch   | 2.56 in  |
| Dimension - N inch                | 0.31 in  |
| Dimension - Outside Diameter inch | 0.63 in  |
| Dimension - Pad Width inch        | 0.48     |
| Dimension - Stud Size fraction    | 1/4      |
| Dimension - Stud Size inch        | 1/4      |
| Dimension - Thread Size           | 1/4 in   |
| Dimension - Z (inch)              | 0.34 in  |
| Physical Attribute - Tongue Angle | Straight |

**Electrical Ratings**

|                   |       |
|-------------------|-------|
| Voltage - Maximum | 35000 |
| Voltage Rating    | 35 kV |

**Conductor Related**

|                                      |           |
|--------------------------------------|-----------|
| Conductor - Copper DLO Size          | 2/0 AWG   |
| Conductor - Copper DLO Size Range    | 2/0 AWG   |
| Conductor - Copper Flex G Size       | "2/0 AWG" |
| Conductor - Copper Flex G Size Range | 2/0 AWG   |
| Conductor - Copper Flex H Size       | "2/0 AWG" |
| Conductor - Copper Flex H Size Range | 2/0 AWG   |
| Conductor - Copper Flex I Size       | "2/0 AWG" |
| Conductor - Copper Flex I Size Range | 2/0 AWG   |
| Conductor - Copper Flex K Size       | "2/0 AWG" |
| Conductor - Copper Flex K Size Range | 2/0 AWG   |
| Conductor - Copper Flex M Size       | "2/0 AWG" |
| Conductor - Copper Str Compact Size  | "2/0 AWG" |

|                                   |                   |
|-----------------------------------|-------------------|
| Conductor - Copper Str Navy Size  | 125               |
| Conductor - Copper Str Size       | "2/0 AWG"         |
| Conductor - Copper Str Size Range | 2/0 AWG           |
| Conductor - CopperWeld Str Size   | 2/0 WELD (325/24) |
| Conductor - Material              | COPPER            |
| Conductor Size                    | 2/0 AWG           |
| Conductor Type                    | CODE/FLEX         |
| Wire Size                         | 2/0 AWG           |

Certifications And Compliance

|                              |                      |
|------------------------------|----------------------|
| Buy America(n) Qualified     | Contact Manufacturer |
| Certification - CSA Approved | Yes                  |
| Industry Standard(s)         | UL 486A-486B         |

|                                    |     |
|------------------------------------|-----|
| Standards - RoHS Compliance Status | CM  |
| UL Listed                          | Yes |

Logistics

|                       |     |
|-----------------------|-----|
| Carton Quantity       | 20  |
| Minimum Pack Quantity | 200 |

Product Assets

- Catalogs - [BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- Customer Notices - [Prop 65 Notice](#)
- Interactive Catalog - [BURNDY Full-Line Digital Catalog](#)
- Sales Drawings - [50054467](#)
- Specifications - [YAV26L2ENT14FX](#)
- Video - [HYDENT Compression Terminal Overview Video](#)

