


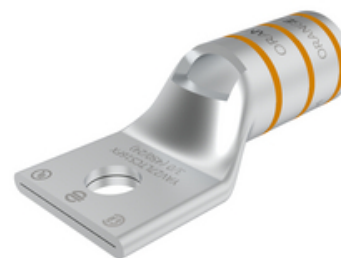

YAV27LTC516FX, Compression Terminal, 3/0 Flex G,H,I,K,M, DLO, 3/0 AWG, Cu, 1-Hole, 5/16" Stud, Standard Barrel

By Burndy
Catalog # [YAV27LTC516FX](#)



3/0 Flex G,H,I,K,M,DLO, 3/0 AWG CU, One Hole, 5/16 Stud Size, Standard Barrel, Inspection Window Internal Chamfer, Tin Plated, UL/CSA, 90°C, Up to 35kV, Orange Color Code, 14 Die Index.

Application

Wire Termination

General

Catalog Number	YAV27LTC516FX
Color Code	Orange
Connector Type	STANDARD BARREL
Die Index	14
EU RoHS Indicator	Yes
Feature - Barrel Style	Chamfered
Feature - Barrel Type	Standard
Finish Type	Tin-Plated
Material	COPPER
Physical Attribute - Number of Holes	1
Plated	Y
Plating Type	Tin - Electro Plated
Sub Brand	HYLUG
Trade Name	HYLUG™
Type	Standard Barrel, Tin Plated
UPC	781810022498
UPC 12 Digit	7818100224988

Dimensions

Dimension - B Length fraction	1 in
Dimension - B Length inch	1.00 in
Dimension - Bolt Hole Size inch	0.33 in
Dimension - Bolt Size fraction	5/16
Dimension - Bolt Size inch	0.3125
Dimension - Hole Size fraction	5/16
Dimension - Hole Size inch	0.38
Dimension - Hole Size mm	10 mm
Dimension - L Length Overall mm	56 mm
Dimension - Length Overall inch	2.21 in
Dimension - N inch	0.34 in
Dimension - Outside Diameter inch	0.70 in
Dimension - Pad Width inch	1.03 in
Dimension - Strip Length inch	1 in
Dimension - Stud Size fraction	5/16
Dimension - Stud Size inch	5/16
Dimension - Z (inch)	0.36 in
Physical Attribute - Tongue Angle	Straight

Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

Conductor Related

Conductor - Copper DLO Size	3/0 AWG
Conductor - Copper DLO Size Range	3/0 AWG
Conductor - Copper Flex G Size	"3/0 AWG"
Conductor - Copper Flex G Size Range	3/0 AWG
Conductor - Copper Flex H Size	"3/0 AWG"
Conductor - Copper Flex H Size Range	3/0 AWG
Conductor - Copper Flex I Size	"3/0 AWG"
Conductor - Copper Flex I Size Range	3/0 AWG
Conductor - Copper Flex K Size	"3/0 AWG"
Conductor - Copper Flex K Size Range	3/0 AWG
Conductor - Copper Flex M Size	"3/0 AWG"
Conductor - Copper Str Compact Size	"3/0 AWG"
Conductor - Copper Str Navy Size	150
Conductor - Copper Str Size	"3/0 AWG"
Conductor - Copper Str Size Range	3/0 AWG
Conductor - CopperWeld Str Size	3/0 E AWG;3/0 EK AWG;3/0 F AWG;3/0 G AWG;3/0 J AWG;3/0 V AWG
Conductor - Material	COPPER
Conductor Size	3/0 AWG
Conductor Type	CODE/FLEX
Wire Size	3/0 AWG

Certifications And Compliance

Buy American Compliant	Yes
Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
Standards - RoHS Compliance	CM
Status	
UL Listed	Yes

Logistics

Carton Quantity	100
Minimum Pack Quantity	100
Pallet Quantity	19600

Product Assets

[3D Models - YAV27LTC516FX_MODEL-PDF](#)
[3D Models - YAV27LTC516FX_MODEL-STEP](#)
[3D Models - YAV27LTC516FX_MODEL-IGES](#)
[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Catalogs - BURNDY Master Catalog - Section C - Compression Connections](#)
[Customer Notices - Prop 65 Notice](#)
[Installation Manuals - Copper Flex Standard Terminals Tooling and Installation Instructions](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Sales Drawings - SE..208001-01](#)
[Video - HYDENT Compression Terminal Overview Video](#)



A Hubbell brand