


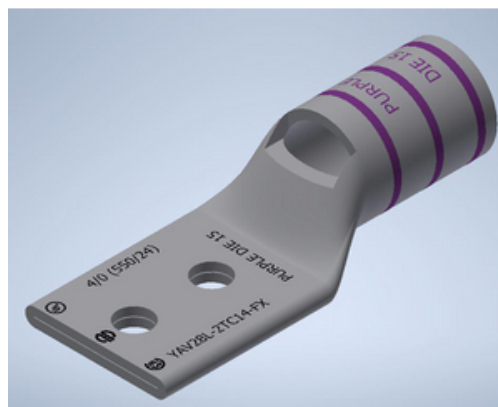

## YAV28L2TC14FX, Cu Compression, 2-Hole, 1/4" Stud, 5/8" Spacing, Standard Barrel, 4/0 Flex

By Burndy  
Catalog # [YAV28L2TC14FX](#)

4/0 Flex G,H,I,K,M,DLO, 4/0 AWG CU, Two Hole, 1/4 Stud Size, 5/8 Hole Spacing, Standard Barrel, Inspection Window, Internal Chamfer, Tin Plated, UL/CSA, 90°C, Up to 35kV, Purple Color Code, 15 Die Index.



### Application

Wire Termination

### General

Catalog Number	YAV28L2TC14FX
Color Code	Purple
Connector Type	STANDARD BARREL
Die Index	15
EU RoHS Indicator	Yes
Feature - Barrel Style	<ul style="list-style-type: none"><li>• Chamfered</li><li>• Skived</li></ul>
Feature - Barrel Type	Standard
Finish Type	Tin-Plated
Material	COPPER
Physical Attribute - Number of Holes	2
Physical Attribute - Tongue Type	Standard
Plated	Y
Plating Type	Tin
Sub Brand	HYLUG
Temperature Rating	194
Trade Name	HYLUG™
Type	Standard Barrel, Tin Plated
UPC	781810103098
UPC 12 Digit	7818101030988

### Dimensions

Dimension - B Length fraction	1 in
Dimension - B Length inch	1.03 in
Dimension - Bolt Hole Size inch	0.27 in
Dimension - Bolt Size fraction	1/4
Dimension - Bolt Size inch	0.25
Dimension - D inch	1.28 in
Dimension - Hole Size fraction	1/4
Dimension - Hole Size inch	0.27
Dimension - Hole Size mm	6.9 mm
Dimension - L Length Overall mm	73 mm
Dimension - Length Overall inch	2.86 in
Dimension - N inch	0.31 in
Dimension - Outside Diameter inch	0.77 in
Dimension - Pad Width inch	1.14 in
Dimension - Strip Length inch	1-1/16
Dimension - Stud Size fraction	1/4
Dimension - Thread Size	1/4 in
Dimension - Z (inch)	0.34 in
Physical Attribute - Tongue Angle	Straight

### Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

## Conductor Related

Conductor - Copper DLO Size	4/0 AWG
Conductor - Copper DLO Size Range	4/0 AWG
Conductor - Copper Flex G Size	"4/0 AWG"
Conductor - Copper Flex G Size Range	4/0 AWG
Conductor - Copper Flex H Size	"4/0 AWG"
Conductor - Copper Flex H Size Range	4/0 AWG
Conductor - Copper Flex I Size	"4/0 AWG"
Conductor - Copper Flex I Size Range	4/0 AWG
Conductor - Copper Flex K Size	"4/0 AWG"
Conductor - Copper Flex K Size Range	4/0 AWG
Conductor - Copper Flex M Size	"4/0 AWG"
Conductor - Copper Flex M Size Range	4/0 AWG
Conductor - Copper Str Compact Size	"4/0 AWG"
Conductor - Copper Str Navy Size	200
Conductor - Copper Str Navy Size Range	200 (61) Navy
Conductor - Copper Str Size	"4/0 AWG"
Conductor - Copper Str Size Range	4/0 AWG
Conductor - CopperWeld Str Size	4/0 E AWG;4/0 EK AWG;4/0 F AWG;4/0 G AWG;4/0 V AWG
Conductor - CopperWeld Str Size Range	4/0 E AWG-4/0 V AWG
Conductor - Material	COPPER
Conductor Size	4/0 AWG
Conductor Type	CODE/FLEX
Wire Size	4/0 AWG

## Certifications And Compliance

Buy American Compliant	Yes
Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
Standards - RoHS Compliance	CM
Status	
UL Listed	Yes

## Logistics

Carton Quantity	100
Minimum Pack Quantity	1
Pallet Quantity	12000

## Product Assets

[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)  
[Catalogs - BURNDY Master Catalog - Section C - Compression Connections](#)  
[Customer Notices - Prop 65 Notice](#)  
[Installation Manuals - Copper Flex Standard Terminals Tooling and Installation Instructions](#)  
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)  
[Sales Drawings - SE..208119-01](#)  
[Specifications - YAV28L2TC14FX](#)  
[Video - HYDENT Compression Terminal Overview Video](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved  
BRDY-YAV28L2TC14FX-SPEC-EN | REV 8/2024