


YAV29LTC38FX, Compression Terminal, 250 kcmil, 4/0 G,H,I,K,M, DLO, Cu, 1-Hole, 3/8" Stud, Standard Barrel

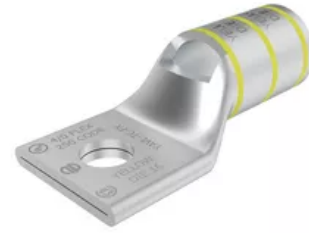

By Burndy

Catalog # [YAV29LTC38FX](#)

250 kcmil, 4/0 G,H,I,K,M,DLO CU, One Hole, 3/8 Stud Size, Standard Barrel, Inspection Window Internal Chamfer, Tin Plated, UL/CSA, 90°C, Up to 35kV, Yellow Color Code, 16 Die Index.

Features

- Electro-tin plated unless otherwise specified to reduce galvanic corrosion (bimetallic) and resist corrosive elements
- Connectors are clearly marked with stamping and barrel color coding
- For applications greater than 2000 Volts consult cable manufacturer for voltage stress relief instructions

Application

Wire Termination

General

Catalog Number	YAV29LTC38FX
Color Code	Yellow
Connector Type	STANDARD BARREL
Die Index	16
EU RoHS Indicator	Yes
Feature - Barrel Style	Chamfered
Feature - Barrel Type	Standard
Finish Type	Tin-Plated
Material	COPPER
Physical Attribute - Number of Holes	1
Plated	Y
Plating Type	Tin
Sub Brand	HYLUG
Trade Name	HYLUG™
Type	Standard Barrel, Tin Plated
UPC	781810279601
UPC 12 Digit	7818102796011

Dimensions

Dimension - B Length fraction	1 in
Dimension - B Length inch	1.03 in
Dimension - Bolt Hole Size inch	0.39 in
Dimension - Bolt Size fraction	3/8
Dimension - Bolt Size inch	0.38
Dimension - Height mm	0 mm
Dimension - Hole Size fraction	3/8

Dimension - Hole Size inch	0.41
Dimension - Hole Size mm	10.4 mm
Dimension - L Length Overall mm	61 mm
Dimension - Length Overall inch	2.42 in
Dimension - N inch	0.41 in
Dimension - Outside Diameter inch	0.80 in
Dimension - Pad Width inch	1.18 in
Dimension - Strip Length inch	1-1/16
Dimension - Stud Size fraction	3/8
Dimension - Stud Size inch	3/8
Dimension - Thread Size	3/8
Dimension - Z (inch)	0.42 in
Physical Attribute - Tongue Angle	Straight

Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

Conductor Related

Conductor - Copper DLO Size	4/0 AWG
Conductor - Copper DLO Size Range	4/0 AWG
Conductor - Copper Flex G Size	"4/0 AWG"
Conductor - Copper Flex G Size Range	4/0 AWG
Conductor - Copper Flex H Size	"4/0 AWG"
Conductor - Copper Flex H Size Range	4/0 AWG
Conductor - Copper Flex I Size	"4/0 AWG"
Conductor - Copper Flex I Size Range	4/0 AWG
Conductor - Copper Flex K Size	"4/0 AWG"
Conductor - Copper Flex K Size Range	4/0 AWG
Conductor - Copper Flex M Size	"4/0 AWG"

Conductor - Copper Str Compact Size	"4/0 AWG"
Conductor - Copper Str Navy Size	200
Conductor - Copper Str Size	"4/0 AWG"
Conductor - Copper Str Size Range	250 kcmil
Conductor - Material	COPPER
Conductor Size	250 KCMIL
Conductor Type	CODE/FLEX
Wire Size	250 KCMIL

Certifications And Compliance

Buy American Compliant	Yes
Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 486A-486B

Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	25
Minimum Pack Quantity	1
Pallet Quantity	14400

Product Assets

- [Catalogs - BURNDY Master Catalog - Section C - Compression Connections](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Installation Manuals - Copper Flex Standard Terminals Tooling and Installation Instructions](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - SE214481-01_C](#)
- [Specifications - YAV29LTC38FX](#)
- [Video - HYDENT Compression Terminal Overview Video](#)



A Hubbell brand