




## YAV4CRS4, Uninsulated Right Angle Ring Terminal For 4 AWG, 1-Hole, 5/16" Stud

By Burndy  
Catalog # [YAV4CRS4](#)

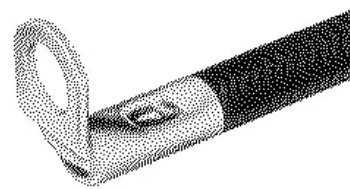

Uninsulated Right Angle Ring Terminal For 4 AWG.

### Features

- Manufactured from seamless pure electrolytic copper tubing to provide maximum conductivity, low resistance and excellent ductility for crimping
- Seamless tubular crimp barrel design - No seams to split resulting in a very high quality electrical connection, also can be used on solid conductor
- Double thick tongue structurally a very strong terminal tongue
- Produced from tubular copper, extra copper material assures the compression connector will operate cooler than the conductors it connects
- Internally bevelled barrel for easy cable entry, especially for flexible conductors
- Inspection hole provides easy visual check for proper conductor insertion
- Electro-tin plated for a long lasting durable corrosion resistance

### Application

For Use On Copper Commercial (Code) Cable, Type AN Aircraft Cable And Extra Flexible Conductors

### General

Catalog Number	YAV4CRS4
Connector Type	Ring Terminal
Die Index	40
EU RoHS Indicator	Yes
Feature - Barrel Style	Chamfered
Feature - Barrel Type	Standard
Material	Copper
Physical Attribute - Number of Holes	1
Physical Attribute - Tongue Type	Ring
Plated	Y
Plating Type	Tin - Electro Plated
Sub Brand	TERMINALS, HYLUG
Trade Name	HYLUG™
Type	Ring Tongue
UPC	781810085721
UPC 14 Digit GTIN	00781810085721

### Dimensions

Dimension - B Length fraction	1/2 in
Dimension - B Length inch	0.50 in
Dimension - Bolt Hole Size inch	0.33 in
Dimension - Bolt Size fraction	5/16
Dimension - G inch	0.96 in
Dimension - Hole Size mm	8 mm
Dimension - L Length Overall mm	25 mm
Dimension - Length Overall inch	1.00 in
Dimension - N inch	0.31 in
Dimension - Outside Diameter inch	0.39 in
Dimension - Pad Width inch	0.62 in
Dimension - Strip Length inch	1/2
Dimension - Stud Size inch	5/16
Dimension - Z (inch)	0.34 in
Physical Attribute - Tongue Angle	90 Degree

### Conductor Related

Conductor - Copper Str Aircraft Size	AN 4
Conductor - Copper Str Size	4
Conductor - Copper Str Size Range	4 AWG
Conductor Size	4 AWG
Conductor Type	<ul style="list-style-type: none"><li>• CU C Solid-Size</li><li>• CU C Str-Size</li></ul>

### Certifications And Compliance

Buy America(n) Qualified	Contact Manufacturer
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - Industry Standards Met	UL486
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	200
Minimum Pack Quantity	1
Pallet Quantity	92800

Product Assets

[3D Models - YAV4CRS4\\_MODEL-PDF](#)

- [3D Models - YAV4CRS4\\_MODEL-IGES](#)
- [3D Models - YAV4CRS4\\_MODEL-STEP](#)
- [Catalogs - BURNDY Master Catalog - Section B - Small Terminals](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR\\_YAV-RS\\_LineArt](#)
- [Sales Drawings - 50094166](#)
- [Specifications - YAV4CRS4](#)



A Hubbell brand