


YAZ2CTC516, Compression Terminal, 2 AWG Cu, 1-Hole, 5/16" Stud, Long Barrel

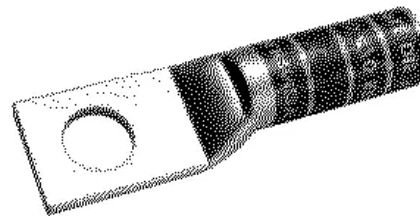

By Burndy

Catalog # [YAZ2CTC516](#)

2 AWG CU, One Hole, 5/16 Stud Size, Long Barrel, Inspection Window, Internal Chamfer, Tin Plated, UL/CSA, 90°C, Up to 35kV, Brown Color Code, 10 Die Index.

Features

- Barrel is designed with an internal chamfer at the wire entry to ensure smooth insertion of the wire, preventing possible damaging of the strands
- Electro-tin plated unless otherwise specified to reduce galvanic corrosion (bimetallic) and resist corrosive elements
- Connectors are clearly marked with stamping and barrel color coding

Application

Wire Termination

General

Catalog Number	YAZ2CTC516
Color Code	Brown
Connector Type	LONG BARREL
Die Index	10
EU RoHS Indicator	Yes
Feature - Barrel Style	Skived
Feature - Barrel Type	Long
Finish Type	Tin-Plated
Material	COPPER
Physical Attribute - Number of Holes	1
Plated	YES
Plating Type	Tin - Electro Plated
Sub Brand	HYLUG
Trade Name	HYLUG™
Type	Long Barrel, Skive, Tin Plated
UPC	781810243435
UPC 12 Digit	7818102434355

Dimensions

Dimension - B Length inch	1.25 in
Dimension - Bolt Hole Size inch	0.33 in
Dimension - Bolt Size fraction	5/16
Dimension - Bolt Size inch	0.3125
Dimension - Hole Size fraction	5/16
Dimension - Hole Size inch	0.38
Dimension - Hole Size mm	10 mm

Dimension - L Length Overall mm	58 mm
Dimension - Length Overall inch	2.27 in
Dimension - N inch	0.34 in
Dimension - Outside Diameter inch	0.42 in
Dimension - Pad Width inch	0.60 in
Dimension - Strip Length inch	1-5/16
Dimension - Stud Size fraction	5/16
Dimension - Z (inch)	0.36 in
Physical Attribute - Tongue Angle	Straight

Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

Conductor Related

Conductor - Copper Str Navy Size	60 (37) Navy
Conductor - Copper Str Size	2 AWG
Conductor - Material	COPPER
Conductor Size	2 AWG
Conductor Type	CODE

Certifications And Compliance

Buy American Compliant	Yes
Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	25
Minimum Pack Quantity	25

Product Assets

[3D Models - YAZ2CTC516_MODEL-STEP](#)

[3D Models - YAZ2CTC516_MODEL-IGES](#)

[3D Models - YAZ2CTC516_MODEL-PDF](#)

[Catalogs - BURNDY Master Catalog - Section C - Compression Connections](#)

[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)

[Customer Notices - Prop 65 Notice](#)

[Installation Manuals - Copper Code Long Terminals Tooling and Installation Instructions](#)

[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)

[Sales Drawings - SE..212356-11](#)

[Specifications - YAZ2CTC516](#)

[Video - HYDENT Compression Terminal Overview Video](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
BRDY-YAZ2CTC516-SPEC-EN | REV 10/2024