


# YAZV4CTC12FX, Compression Terminal, 4 Weld 91/24, 105/24, 1-Hole, 1/2" Stud, Long Barrel

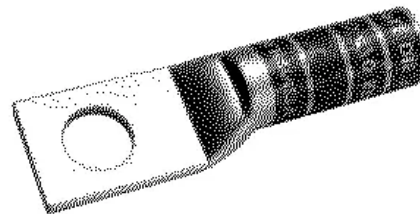

By Burndy  
Catalog # [YAZV4CTC12FX](#)

Cu compression long barrel flex conductor, single hole/W/ insp window, #4 weld(91/24)(105/24), 1/2" stud, Grey, 8 or 346 index.

## Features

- Barrel is designed with an internal chamfer at the wire entry to ensure smooth insertion of the wire, preventing possible damaging of the strands
- Electro-tin plated unless otherwise specified to reduce galvanic corrosion (bimetallic) and resist corrosive elements
- Connectors are clearly marked with stamping and barrel color coding

## Application

Wire Termination

## General

Catalog Number	YAZV4CTC12FX
Color Code	Gray
Connector Type	LONG BARREL
Die Index	8
EU RoHS Indicator	Yes
Feature - Barrel Style	Skived
Feature - Barrel Type	Long
Finish Type	Tin-Plated
Material	COPPER
Physical Attribute - Number of Holes	1
Plated	Y
Plating Type	Tin
Sub Brand	TERMINALS, HYLUG
Trade Name	HYLUG™
Type	Long Barrel, Skive
UPC	781810491010
UPC 12 Digit	7818104910100

## Dimensions

Dimension - B Length fraction	1-1/4 in
Dimension - B Length inch	1.25 in
Dimension - Bolt Hole Size inch	0.52 in
Dimension - Bolt Size fraction	1/2
Dimension - Bolt Size inch	0.5
Dimension - Hole Size fraction	1/2
Dimension - Hole Size inch	0.53
Dimension - Hole Size mm	13.5 mm

Dimension - L Length Overall mm	68 mm
Dimension - Length Overall inch	2.67 in
Dimension - N inch	0.53 in
Dimension - Outside Diameter inch	0.38 in
Dimension - Pad Width inch	0.71 in
Dimension - Strip Length inch	1-5/16
Dimension - Stud Size fraction	1/2
Dimension - Z (inch)	0.54 in
Physical Attribute - Tongue Angle	Straight

## Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

## Conductor Related

Conductor - Copper DLO Size	4 AWG
Conductor - Copper DLO Size Range	4 AWG
Conductor - Copper Flex G Size	"4 AWG"
Conductor - Copper Flex G Size Range	4 AWG
Conductor - Copper Flex H Size	"4 AWG"
Conductor - Copper Flex H Size Range	4 AWG
Conductor - Copper Flex I Size	"4 AWG"
Conductor - Copper Flex I Size Range	4 AWG
Conductor - Copper Flex K Size	"4 AWG"
Conductor - Copper Flex K Size Range	4 AWG
Conductor - Copper Flex M Size	"4 AWG"
Conductor - Copper Flex M Size Range	4 AWG
Conductor - Copper Str Compact Size	"4 AWG"
Conductor - Copper Str Navy Size	40

Conductor - Copper Str Size	"4 AWG"
Conductor - Copper Str Size Range	4 AWG
Conductor - CopperWeld Str Size	4 A AWG;4 D AWG;4 N AWG;4 P AWG
Conductor - CopperWeld Str Size Range	4 A AWG-4 P AWG
Conductor - Material	COPPER
Conductor Size	4 AWG
Conductor Type	CODE/FLEX
Wire Size	4 AWG

### Certifications And Compliance

Buy American Compliant	No
Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 486A-486B

Standards - RoHS Compliance Status	CM
UL Listed	Yes

### Logistics

Carton Quantity	50
Minimum Pack Quantity	50

### Product Assets

- [3D Models - YAZV4CTC12FX\\_MODEL-PDF](#)
- [3D Models - YAZV4CTC12FX\\_MODEL-IGES](#)
- [3D Models - YAZV4CTC12FX\\_MODEL-STEP](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - SE..212448-03](#)
- [Specifications - YAZV4CTC12FX](#)
- [Video - HYDENT Compression Terminal Overview Video](#)



A Hubbell brand