


# YC10C10, Copper C-Shape Connector

By Burndy  
Catalog # YC10C10

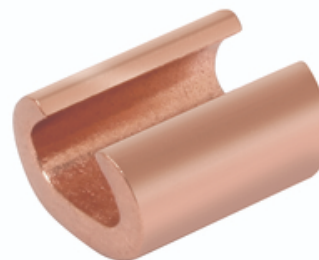

Range-taking compression tap connector made of pure copper. For Copper to Copper applications and used for deadending.

## Application

For Range Of Copper And Making Tap Or Parallel Copper Connections

## General

Catalog Number	YC10C10
Die Index	238
EU RoHS Indicator	Yes
Material	Copper
Plated	N
Plating Type	Unplated
Sub Brand	CRIMPIT
Trade Name	CRIMPIT™
Type	YC-C Series
UPC	781810114605
UPC 12 Digit	7818101146055

## Dimensions

Dimension - Height inch	0.37 in
Dimension - L Length Overall mm	8.1 mm
Dimension - Length Overall inch	0.32 in

## Conductor Related

Conductor - Copper Str Run Range	12 Sol. - 10 Str
Conductor - Copper Str Tap Range	12 Sol. 10 Str
Conductor Type	Cu C Sol-Size

## Certifications And Compliance

Buy American Compliant	Yes
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	<ul style="list-style-type: none"> <li>UL 486A</li> <li>UL486B</li> </ul>
Standards - Industry Standards Met	UL 486A;UL486B
Standards - RoHS Compliance Status	CM
UL Listed	No

## Logistics

Carton Quantity	1000
Minimum Pack Quantity	1
Pallet Quantity	99999

## Product Assets

- [3D Models - YC10C10\\_MODEL-IGES](#)
- [3D Models - YC10C10\\_MODEL-STEP](#)
- [3D Models - YC10C10\\_MODEL-PDF](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section H - Overhead Distribution](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR\\_YCC\\_Lineart](#)
- [Sales Drawings - SE..090670-01](#)
- [Sell Sheets - CRIMPIT™ Family](#)
- [Specifications - YC10C10](#)