




# YC26C2, Copper C-Shape Connector

By Burndy  
Catalog # [YC26C2](#)

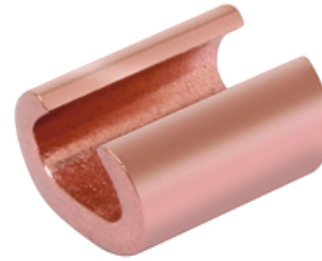

CU Compression C Shape Compression Connector, 600 Volts to 35 Kv, Run: 1/0 Str. - 2/0 Str., Tap: 8 Sol. - 2 Str.

## Application

For Making Tap Or Parallel Copper Connections

## General

Die Index	E or O
EU RoHS Indicator	Yes
Material	Copper
Plated	N
Plating Type	Unplated
Sub Brand	CRIMPIT
Trade Name	CRIMPIT™
Type	YC-C Series
UPC	781810114803
UPC 12 Digit	7818101148033

## Dimensions

Dimension - Height inch	1.30 in
Dimension - L Length Overall mm	23 mm
Dimension - Length Overall inch	0.92 in

## Conductor Related

Conductor - Copper Str Run Range	1/0 -2/0 AWG
Conductor - Copper Str Tap Range	8 Sol. - 2 Str

## Certifications and Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	<ul style="list-style-type: none"><li>UL 486A</li><li>UL486B</li></ul>
Standards - Industry Standards Met	<ul style="list-style-type: none"><li>UL 486A</li><li>UL486B</li></ul>
Standards - RoHS Compliance Status	CM
UL Listed	Yes

## Logistics

Carton Quantity	50
Minimum Pack Quantity	1
Pallet Quantity	11600

## Product Assets

[3D Models - YC26C2\\_MODEL-PDF](#)  
[3D Models - YC26C2\\_MODEL-IGES](#)  
[3D Models - YC26C2\\_MODEL-STEP](#)  
[Catalogs - Full Line BURNDY Catalog](#)  
[Customer Notices - Prop 65 Notice](#)  
[Sales Drawings - SE..090670-01](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
BRDY-YC26C2-SPEC-EN | REV 8/2023