


YC28C26, Copper C-Shape Connector

By Burndy
Catalog # [YC28C26](#)

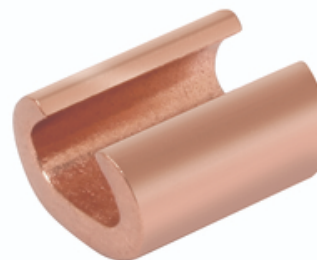

CU Compression C Shape Compression Connector, 600 Volts to 35 Kv, Run: 3/0 Str. - 4/0 Str., Tap: 1/0 Str. - 2/0 Str.

Application

For Making Tap Or Parallel Copper Connections

General

Catalog Number	YC28C26
Die Index	F or D3
EU RoHS Indicator	Yes
Material	Copper
Plated	N
Plating Type	Unplated
Sub Brand	CRIMPIT
Trade Name	CRIMPIT™
Type	YC-C Series
UPC	781810116005
UPC 12 Digit	7818101160055

Dimensions

Dimension - Height inch	1.61 in
Dimension - L Length Overall mm	27 mm
Dimension - Length Overall inch	1.07 in

Conductor Related

Conductor - Copper Str Run Range	3/0 AWG-4/0 AWG
Conductor - Copper Str Tap Range	1/0 AWG-2/0 AWG

Certifications And Compliance

Buy American Compliant	Yes
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	<ul style="list-style-type: none">UL 486AUL486B
Standards - Industry Standards Met	UL 486A;UL486B
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	25
Minimum Pack Quantity	1
Pallet Quantity	5800

Product Assets

[3D Models - YC28C26_MODEL-PDF](#)
[3D Models - YC28C26_MODEL-STEP](#)
[3D Models - YC28C26_MODEL-IGES](#)
[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Catalogs - BURNDY Master Catalog - Section H - Overhead Distribution](#)
[Customer Notices - Prop 65 Notice](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Product Cross Section Image\(s\) - BUR_YCC_Lineart](#)
[Sales Drawings - SE..090670-01](#)