


YC28C28, Copper C-Shape Connector

By Burndy
Catalog # [YC28C28](#)

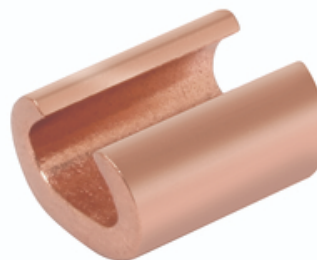

CU Compression C Shape Compression Connector, 600 Volts to 35 Kv, 3/0 Str. - 4/0 Str. (Run & Tap).

Application

For Making Tap Or Parallel Copper Connections

General

Catalog Number	YC28C28
Die Index	F or D3
EU RoHS Indicator	Yes
Material	Copper
Plated	N
Plating Type	Unplated
Sub Brand	CRIMPIT
Trade Name	CRIMPIT™
Type	YC-C Series
UPC	781810116302
UPC 12 Digit	7818101163022

Dimensions

Dimension - Height inch	1.56 in
Dimension - L Length Overall mm	27 mm
Dimension - Length Overall inch	1.07 in

Conductor Related

Conductor - Copper Str Run Range	3/0 AWG-4/0 AWG
Conductor - Copper Str Tap Range	3/0 AWG-4/0 AWG

Certifications And Compliance

Buy American Compliant	Yes
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	<ul style="list-style-type: none"> • UL 486A • UL486B
Standards - Industry Standards Met	UL 486A;UL486B
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	50
Minimum Pack Quantity	1
Pallet Quantity	7400

Product Assets

- [3D Models - YC28C28_MODEL-IGES](#)
- [3D Models - YC28C28_MODEL-PDF](#)
- [3D Models - YC28C28_MODEL-STEP](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section H - Overhead Distribution](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR_YCC_Lineart](#)
- [Sales Drawings - SE..090670-01](#)