



YC28U26, Figure 6-Shape Tap Connector

By Burndy
Catalog # [YC28U26](#)

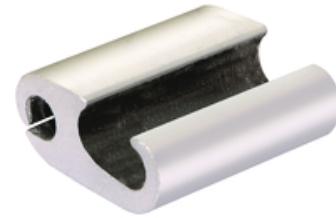


Figure 6- shaped, wide range-taking aluminum compression tap connector Run: Al & Cu: 1/0 - 4/0 Kcmil, ACSR: 1/0 - 4/0, Tap: 6 - 2/0 AWG, ACSR: 6 -1/0.

General

Die Index	H
Plated	N
Plating Type	Unplated
Trade Name	CRIMPIT™
Type	YC-A, YC-U Series
UPC	781810126479
UPC 12 Digit	7818101264799

Dimensions

Dimension - Height inch	2.06 in
Dimension - L Length Overall mm	54 mm
Dimension - Length Overall inch	2.12 in

Conductor Related

Conductor - ACSR Str Run Range	1/0 AWG - 4/0 AWG
Conductor - ACSR Str Tap Range	6 AWG - 1/0 AWG
Conductor - AL Str Run Range	1/0 AWG - 4/0 AWG
Conductor - AL Str Tap Range	6 AWG - 2/0 AWG
Conductor - Copper Solid Run Range	18 AWG
Conductor - Copper Solid Tap Range	6 AWG
Conductor - Copper Str Run Range	1/0 -4/0 AWG
Conductor - Copper Str Tap Range	6 AWG - 2/0 AWG

Certifications and Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	25
Minimum Pack Quantity	1
Pallet Quantity	6000

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - sd042248-01](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRDY-YC28U26-SPEC-EN | REV 8/2023