



YC33R26U, Aluminum Figure 6-Shape Connector

By Burndy
Catalog # [YC33R26U](#)

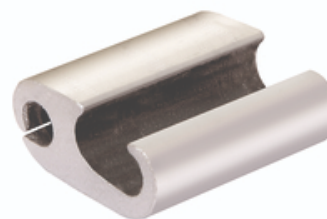


Figure 6- shaped, wide range-taking aluminum compression tap connector Run: Al & Cu: 300 -397.5 Kcmil, ACSR: 266.8 -336.4 Kcmil, Tap: 6-2/0 AWG, ACSR: 4 -1/0.

General

Catalog Number	YC33R26U
Die Index	R
Plated	N
Plating Type	Unplated
Trade Name	CRIMPIT™
Type	YC-A, YC-U Series
UPC	781810127100
UPC 12 Digit	7818101271000

Dimensions

Dimension - Height inch	2.25 in
Dimension - L Length Overall mm	54 mm
Dimension - Length Overall inch	2.12 in

Conductor Related

Conductor - ACSR Str Run Range	6 AWG - 2/0 AWG
Conductor - ACSR Str Tap Range	6 AWG - 1/0 AWG
Conductor - AL Str Run Range	300 Kcmil - 397.5 Kcmil
Conductor - AL Str Tap Range	6 AWG - 2/0 AWG
Conductor - Copper Solid Run Range	18 AWG
Conductor - Copper Solid Tap Range	6 AWG
Conductor - Copper Str Run Range	300 Kcmil - 397.5 Kcmil
Conductor - Copper Str Tap Range	6 AWG - 2/0 AWG

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance	CM
Status	
UL Listed	No

Logistics

Carton Quantity	25
Minimum Pack Quantity	1
Pallet Quantity	6000

Product Assets

[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Catalogs - BURNDY Master Catalog - Section H - Overhead Distribution](#)
[Customer Notices - Prop 65 Notice](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Product Cross Section Image\(s\) - BUR_YCU_LineArt](#)
[Sales Drawings - sd042248-01](#)
[Specifications - YC33R26U](#)