




YC8C8, Copper C-Shape Connector

By Burndy
Catalog # YC8C8

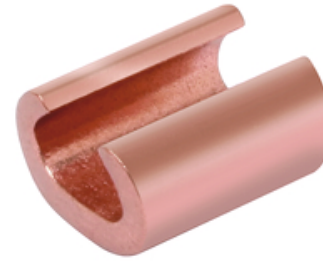

CU Compression C Shape Compression Connector, 600 Volts to 35 Kv, Run: 8 Sol. - 8 Str., Tap: 10 Sol. - 8 Str.

Application

For Making Tap Or Parallel Copper Connections

General

Die Index	162
EU RoHS Indicator	Yes
Material	Copper
Plated	N
Plating Type	Unplated
Sub Brand	CRIMPIT
Trade Name	CRIMPIT™
Type	YC-C Series
UPC	781810114506
UPC 12 Digit	7818101145066

Dimensions

Dimension - Height inch	0.46 in
Dimension - L Length Overall mm	13 mm
Dimension - Length Overall inch	0.50 in

Conductor Related

Conductor - Copper Solid Run	8 AWG
Conductor - Copper Solid Tap	10 AWG;9 AWG;8 AWG
Conductor - Copper Solid Tap Range	10 Sol. - 8 Str.
Conductor - Copper Str Run	8 AWG
Conductor - Copper Str Tap Range	10 Sol. - 8 Str.
Conductor Type	Cu C Sol-Size

Certifications and Compliance

Certification - CSA Approved	No
Industry Standard(s)	<ul style="list-style-type: none">UL 486AUL486B
Standards - Industry Standards Met	UL 486A;UL486B
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	100
Minimum Pack Quantity	1

Product Assets

[3D Models - YC8C8_MODEL-PDF](#)
[3D Models - YC8C8_MODEL-STEP](#)
[3D Models - YC8C8_MODEL-IGES](#)
[Catalogs - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - SE..090670-01](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRDY-YC8C8-SPEC-EN | REV 8/2023