


## YCS011R, Aluminum Loop Splice

By Burndy  
Catalog # [YCS011R](#)

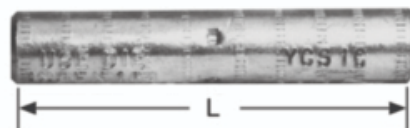

Al Compression Loop Splice, 80 kcmil ACSR.

### General

Catalog Number	YCS011R
Connector Type	Splice
Die Index	245
Material	Aluminum
Plated	N
Plating Type	Unplated
Prefilled Oxide Inhibitor	Y
Trade Name	HYSPLICE™
UPC	781810096697
UPC 12 Digit	7818100966977

### Dimensions

Dimension - B Length inch	3.55 in
Dimension - L Length Overall mm	182 mm
Dimension - Length Overall inch	7.18 in
Dimension - Outside Diameter inch	0.7 in

### Conductor Related

Conductor - ACSR Str Size	80 (8/1) Grouse kcmil
Conductor - ACSR Str Size Range	80 (8/1) Grouse kcmil

### Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance	CM
Status	
UL Listed	No

### Logistics

Carton Quantity	25
Minimum Pack Quantity	1
Pallet Quantity	9800

### Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - 50115707](#)
- [Specifications - YCS011R](#)