




# YCS25RL, Aluminum Sleeve, Staked Cable Stop

By Burndy  
Catalog # [YCS25RL](#)

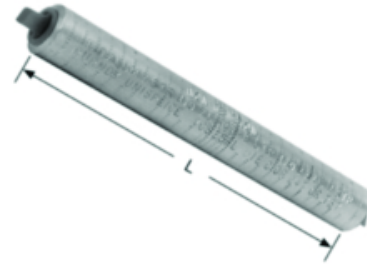

HYSPLICE AL sleeve with staked cable stop, designed to withstand jumper loop tensile and vibration stresses. ANSI C119.4 CLASS 2 (PARTIAL TENSION), 6-1/4 IN L.

## Application

For ACSR, All Aluminum 6201, 5005 Compressed And Compact Conductors

## General

Connector Type	Splice
Die Index	C or 247
EU RoHS Indicator	Yes
Material	Aluminum
Plated	N
Plating Type	Unplated
Prefilled Oxide Inhibitor	Y
Sub Brand	UNISPLICE
Trade Name	UNISPLICE™
Type	YCS-RL
UPC	781810014998
UPC 12 Digit	7818100149988

## Dimensions

Dimension - B Length inch	3.03 in
Dimension - L Length Overall mm	158 mm
Dimension - Length Overall inch	6.22 in
Dimension - Outside Diameter inch	0.8 in

## Conductor Related

Conductor - AAAC 5005 Size	1/0 (7) AWG
Conductor - AAAC 5005 Size Range	1/0 (7) AWG
Conductor - AAAC 6201 Size	1/0 (7) AWG
Conductor - AAAC 6201 Size Range	1/0 (7) AWG
Conductor - ACSR Str Size	1/0 (6/1) Raven AWG
Conductor - ACSR Str Size Range	1/0 (6/1) Raven AWG
Conductor - AL Str Size	1/0 (7) AWG
Conductor - AL Str Size Range	1/0 (7) AWG

## Certifications and Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

## Logistics

Carton Quantity	25
Minimum Pack Quantity	25
Pallet Quantity	9800

## Product Assets

- [3D Models - YCS25RL\\_MODEL-STEP](#)
- [3D Models - YCS25RL\\_MODEL-IGES](#)
- [3D Models - YCS25RL\\_MODEL-PDF](#)
- [Catalogs - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Sales Drawings - SD..052277-01](#)



A proud member of the Hubbell Family.