


## YCS25RLELN, Aluminum Sleeve, Staked Cable Stop

By Burndy  
Catalog # [YCS25RLELN](#)

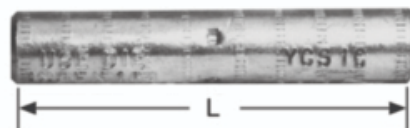

HYSPLICE Aluminum sleeve with staked cable stop, designed to withstand jumper loop tensile and vibration stresses. ANSI C119.4 CLASS 2 (PARTIAL TENSION).

### General

Catalog Number	YCS25RLELN
Connector Type	Splice
Die Index	247
Material	Aluminum
Plated	N
Plating Type	Unplated
Prefilled Oxide Inhibitor	Y
Trade Name	UNISPLICE™
UPC	781810250167
UPC 12 Digit	7818102501677

### Dimensions

Dimension - L Length Overall mm	158 mm
Dimension - Length Overall inch	6.22 in

### Conductor Related

Conductor - ACSR Cmpt Size	1/0 AWG
Conductor - ACSR Cmpt Size Range	1/0 AWG
Conductor - ACSR Str Size	1/0 (6/1) Raven AWG
Conductor - ACSR Str Size Range	1/0 (6/1) Raven AWG
Conductor - AL Str Size	1/0 AWG
Conductor - AL Str Size Range	1/0 AWG

### Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance	CM
Status	
UL Listed	No

### Logistics

Carton Quantity	25
Minimum Pack Quantity	1
Pallet Quantity	9800

### Product Assets

[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)  
[Customer Notices - Prop 65 Notice](#)  
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)  
[Specifications - YCS25RLELN](#)