


YCS271R, Copper Loop Splice

By Burndy
Catalog # YCS271R

Al Compression Loop Splice, 159 kcmil ACSR.

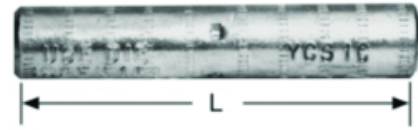

General

Connector Type	Splice
Die Index	317
Material	Aluminum
Plated	N
Plating Type	Unplated
Prefilled Oxide Inhibitor	Y
Trade Name	HYSPLICE™
UPC	781810178850
UPC 12 Digit	7818101788500

Dimensions

Dimension - B Length inch	4.31 in
Dimension - L Length Overall mm	224 mm
Dimension - Length Overall inch	8.80 in
Dimension - Outside Diameter inch	1.25 in

Conductor Related

Conductor - ACSR Str Size	159 (12/7) Guinea kcmil
Conductor - ACSR Str Size Range	159 (12/7) Guinea kcmil

Certifications and Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	10
Minimum Pack Quantity	1
Pallet Quantity	2400

Product Assets

[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - 50115707](#)