




# YCS28RL, Aluminum Sleeve, Staked Cable Stop

By Burndy  
Catalog # [YCS28RL](#)

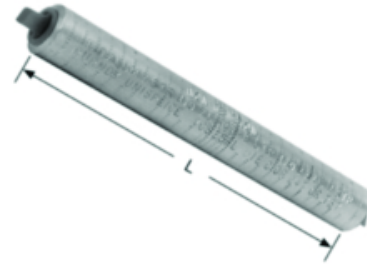

HYSPLICE AL sleeve with staked cable stop, designed to withstand jumper loop tensile and vibration stresses. ANSI C119.4 CLASS 2 (PARTIAL TENSION), 5-1/4 IN L.

## General

Connector Type	Splice
Die Index	654
Material	Aluminum
Plated	N
Plating Type	Unplated
Prefilled Oxide Inhibitor	Y
Trade Name	UNISPLICE™
UPC	781810820506
UPC 12 Digit	7818108205066

## Dimensions

Dimension - B Length inch	2.44 in
Dimension - L Length Overall mm	131 mm
Dimension - Length Overall inch	5.16 in
Dimension - Outside Diameter inch	1.02 in

## Conductor Related

Conductor - AAAC 5005 Size	4/0 AWG
Conductor - AAAC 6201 Size	4/0 AWG
Conductor - ACSR Str Size	4/0 (6/1) Penguin AWG
Conductor - AL Str Size	4/0 AWG

## Certifications and Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

## Logistics

Carton Quantity	25
Minimum Pack Quantity	25
Pallet Quantity	7400

## Product Assets

[Customer Notices - Prop 65 Notice](#)  
[Sales Drawings - SD..052277-01](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
BRDY-YCS28RL-SPEC-EN | REV 8/2023