




# YCS2R, Aluminum Sleeve, Staked Cable Stop

By Burndy  
Catalog # YCS2R

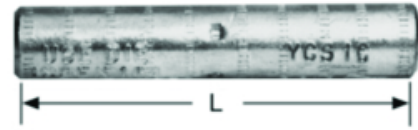

HYSPLICE AL sleeve with staked cable stop, designed to withstand jumper loop tensile and vibration stresses. ANSI C119.4 CLASS 2 (PARTIAL TENSION), 5 IN L.

## Application

The sleeves designed to withstand jumper loop tensile and vibration stresses.

## General

Connector Type	Splice
Construction Material - Main	Aluminum
Die Index	239
EU RoHS Indicator	Contact Manufacturer
Material	Aluminum
Plated	N
Plating Type	Unplated
Prefilled Oxide Inhibitor	Y
Sub Brand	HYSPLICE
Trade Name	HYSPLICE™
Type	YCS-R
UPC	781810014974
UPC 12 Digit	7818100149744

## Dimensions

Dimension - B Length inch	2.38 in
Dimension - L Length Overall mm	125 mm
Dimension - Length Overall inch	4.91 in
Dimension - Outside Diameter inch	0.5 in

## Conductor Related

Conductor - AAAC 5005 Size	77.47 (7) kcmil
Conductor - AAAC 5005 Size Range	77.47 (7) kcmil
Conductor - AAAC 6201 Size	77.47 (7) kcmil
Conductor - ACSR Str Size	2 (6/1) Sparrow AWG;2 (7/1) Sparate AWG
Conductor - AL Str Size	2 AWG

## Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

## Logistics

Carton Quantity	25
Minimum Pack Quantity	1
Pallet Quantity	24000

## Product Assets

[Catalogs - Full Line BURNDY Catalog](#)  
[Customer Notices - Prop 65 Notice](#)  
[Product Cross Section Image\(s\) - BUR\\_YCS-R\\_LineArt](#)  
[Sales Drawings - 50115707](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.  
BRDY-YCS2R-SPEC-EN | REV 5/2024