




YCS35R, Aluminum Sleeve, Staked Cable Stop

By Burndy
Catalog # [YCS35R](#)

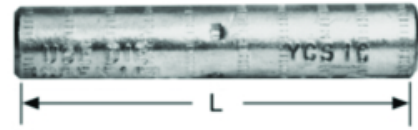

HYSPLICE AL sleeve with staked cable stop, designed to withstand jumper loop tensile and vibration stresses. ANSI C119.4 CLASS 2 (PARTIAL TENSION), 8-7/8 IN L.

Application

For ACSR, All Aluminum, 6201, 5005 And Compressed Conductors

General

Connector Type	Splice
Die Index	317
EU RoHS Indicator	Yes
Material	Aluminum
Plated	N
Plating Type	Unplated
Prefilled Oxide Inhibitor	Y
Sub Brand	HYSPLICE
Trade Name	HYSPLICE™
Type	YCS-R
UPC	781810821114
UPC 12 Digit	7818108211144

Dimensions

Dimension - B Length fraction	4-22/71 in
Dimension - B Length inch	4.31 in
Dimension - L Length Overall mm	224 mm
Dimension - Length Overall inch	8.8 in

Conductor Related

Conductor - AAAC 5005 Size	465.4 (19)
Conductor - AAAC 5005 Size Range	465.4 (19)
Conductor - AAAC 6201 Size	465.4 (19)
Conductor - AAAC 6201 Size Range	465.4 (19)
Conductor - ACSR Str Size	397.5 (18/1) Chickadee;397.5 (26/7) Ibis;397.5 (30/7) Lark
Conductor - ACSR Str Size Range	397.5 (18/1) Chickadee-397.5 (30/7) Lark
Conductor - AL Str Size	397.5
Conductor - AL Str Size Range	397.5

Certifications and Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	25
Minimum Pack Quantity	25
Pallet Quantity	3600

Product Assets

[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - 50115707](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRDY-YCS35R-SPEC-EN | REV 8/2023