


## YCS37R, Aluminum Sleeve, Staked Cable Stop

By Burndy  
Catalog # YCS37R

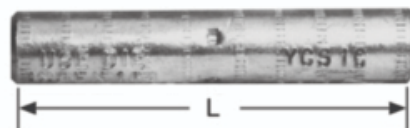

HYSPLICE AL sleeve with staked cable stop, designed to withstand jumper loop tensile and vibration stresses. ANSI C119.4 CLASS 2 (PARTIAL TENSION), Index:261.

### Application

For ACSR, All Aluminum, 6201, 5005 And Compressed Conductors

### General

Catalog Number	YCS37R
Connector Type	Splice
Die Index	261
EU RoHS Indicator	Yes
Material	Aluminum
Plated	N
Plating Type	Unplated
Prefilled Oxide Inhibitor	Y
Sub Brand	HYSPLICE
Trade Name	HYSPLICE™
Type	YCS-R
UPC	781810015063
UPC 12 Digit	7818100150633

### Dimensions

Dimension - B Length fraction	4-22/71 in
Dimension - B Length inch	4.31 in
Dimension - L Length Overall mm	222 mm
Dimension - Length Overall inch	8.75 in

### Conductor Related

Conductor - AAAC 5005 Size Range	559.5 (19)
Conductor - AAAC 6201 Size Range	559.5 (19)
Conductor - ACSR Str Size	477.0 (24/7) Flicker;477.0 (26/7) Hawk;477.0 (30/7) Hen
Conductor - ACSR Str Size Range	477.0 (24/7) Flicker-477.0 (30/7) Hen
Conductor - AL Str Size	556.5
Conductor - AL Str Size Range	556.5

### Certifications And Compliance

Buy American Compliant	Yes
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

### Logistics

Carton Quantity	20
Minimum Pack Quantity	1
Pallet Quantity	2880

### Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section H - Overhead Distribution](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR\\_YCS-R\\_LineArt](#)
- [Sales Drawings - 50115707](#)
- [Specifications - YCS37R](#)



A Hubbell brand