


YCS49R, Aluminum Splice, Single Sleeve Jumper

By Burndy
Catalog # [YCS49R](#)

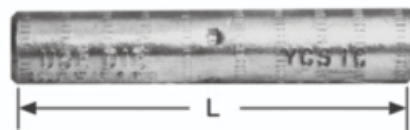

Al Tube Compression Splice, Single Sleeve Jumper Partial Tension, 954 - 1033.5 kcmil ACSR.

General

Catalog Number	YCS49R
Connector Type	Splice
Die Index	575
Material	Aluminum
Plated	N
Plating Type	Unplated
Prefilled Oxide Inhibitor	Y
Trade Name	HYSPLICE™
UPC	781810129425
UPC 12 Digit	7818101294255

Dimensions

Dimension - B Length fraction	6-1/10 in
Dimension - B Length inch	6.1 in
Dimension - L Length Overall mm	313 mm
Dimension - Length Overall inch	12.32 in

Conductor Related

Conductor - ACSR Str Size	954 (54/7) Cardinal kcmil;1033.5 (45/7) Ortolan kcmil;1033.5 (54/7) Curlew kcmil
Conductor - ACSR Str Size Range	954 (54/7) Cardinal kcmil-1033.5 (54/7) Curlew kcmil
Conductor - AL Str Size	954 kcmil
Conductor - AL Str Size Range	954 kcmil

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	8
Minimum Pack Quantity	8
Pallet Quantity	720

Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - 54439](#)
- [Specifications - YCS49R](#)