


YDR4WG1, Copper Reducer

By Burndy
Catalog # [YDR4WG1](#)

Copper Hyreducer, # 4 Sol. (Barrel A) , #6 Sol. (Barrel B).

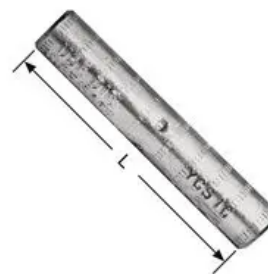

Application

Splice

General

Catalog Number	YDR4WG1
Connector Type	Splice
Die Index	162
EU RoHS Indicator	Yes
Material	Copper
Physical Attribute - Number of	4
Crimps Required	
Plated	N
Plating Type	Unplated
Prefilled Oxide Inhibitor	N
Sub Brand	COMPRESSION TERMINAL
Trade Name	HYREDUCER™
Type	Terminal
UPC	781810014424

Dimensions

Dimension - A Outside Diameter inch	0.42 in
Dimension - B Length fraction	1-1/4 in
Dimension - B Length inch	1.25 in
Dimension - B Outside Diameter inch	0.38 in
Dimension - L Length Overall mm	67 mm
Dimension - Length BB inch	1.25 in
Dimension - Length Overall inch	2.65 in

Conductor Related

Conductor - Copper Solid Size A	4 AWG
Conductor - Copper Solid Size A Range	4 AWG
Conductor - Copper Solid Size B	6 AWG
Conductor - Copper Solid Size B Range	4 AWG

Certifications And Compliance

Buy American Compliant	Yes
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	100
Minimum Pack Quantity	1
Pallet Quantity	29000

Product Assets

- [3D Models - YDR4WG1_MODEL-STEP](#)
- [3D Models - YDR4WG1_MODEL-PDF](#)
- [3D Models - YDR4WG1_MODEL-IGES](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR_YCS-A_LineArt](#)
- [Sales Drawings - SD..042723-01_B Model \(1\)](#)
- [Specifications - YDR4WG1](#)