


# YDS4C, Copper, Single Sleeve Full Tension Splice

By Burndy  
Catalog # YDS4C

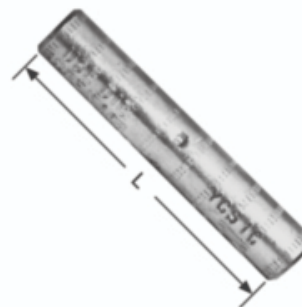

HYSPLICE Single Sleeve Full Tension Splice, Accommodates Wire: #4 Cu STR (Hard, Medium, or Soft Drawn), Die Index: 162, Made of copper tubing, Installed with standard tools and dies.

## Application

For Stranded Copper Conductors

## General

Catalog Number	YDS4C
Connector Type	Splice
Die Index	162
EU RoHS Indicator	Yes
Material	Copper
Oxide Inhibitor Type	Penetrox E
Physical Attribute - Number of Crimps Required	1
Plated	N
Plating Type	Unplated
Prefilled Oxide Inhibitor	Y
Sub Brand	HYSPLICE
Trade Name	HYSPLICE™
Type	YDS - C
UPC	781810821060

## Dimensions

Dimension - B Length fraction	1-3/20 in
Dimension - B Length inch	1.15 in
Dimension - L Length Overall mm	65 mm
Dimension - Length Overall inch	2.55 in
Dimension - Outside Diameter inch	0.40 in

## Conductor Related

Conductor - Copper Str Size 4 AWG

## Certifications And Compliance

Buy American Compliant	Yes
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

## Logistics

Carton Quantity	100
Minimum Pack Quantity	1
Pallet Quantity	34800

## Product Assets

- [3D Models - YDS4C\\_MODEL-STEP](#)
- [3D Models - YDS4C\\_MODEL-IGES](#)
- [3D Models - YDS4C\\_MODEL-PDF](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section H - Overhead Distribution](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR\\_YDS\\_LineArt](#)
- [Sales Drawings - 50115709](#)
- [Specifications - YDS4C](#)