


YF0418IDL, Covered Ferrule For 4 AWG

By Burndy
Catalog # [YF0418IDL](#)

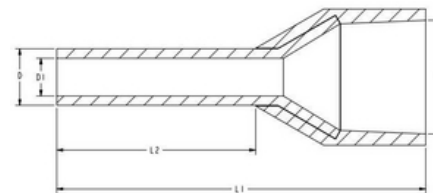

Covered Ferrule For 4 AWG.

Features

- Made of electrolytic copper, tin plated
- Smooth funnel entry to make wire insertion easier
- Secure contacting even after multiple reconnections
- Long-term contact resistance
- No fraying of strands
- No breakage of wire strands when wire is bent, under stress, or in vibration environment
- UL listed per UL486F requirements
- RoHS Compliant

Application

For Use On Copper Conductor

General

Catalog Number	YF0418IDL
Connector Type	End Termination
EU RoHS Indicator	Yes
Insulation	Y
Material	Copper
Plated	Y
Plating Type	Tin - Electro Plated
Sub Brand	FERRULES
Type	Bootlace Ferrule
UPC	621945622494

Dimensions

Dimension - D inch	0.30 in
Dimension - D1 inch	0.29 in

Dimension - D2 inch	0.44 in
Dimension - Length Overall inch	1.26 in

Conductor Related

Conductor - Copper Solid Size	4 AWG
Conductor - Copper Str Size	4 AWG
Conductor Size	4 AWG

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - Industry Standards	UL486
Met	
Standards - RoHS Compliance	CM
Status	
UL Listed	Yes

Logistics

Carton Quantity	100
Minimum Pack Quantity	100

Product Assets

[Catalogs - BURNDY Master Catalog - Section B - Small Terminals](#)
[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Sales Drawings - 5011876](#)
[Specifications - YF0418IDL](#)