


# YF1010ITL, Covered Ferrule For 10 AWG

By Burndy  
Catalog # [YF1010ITL](#)

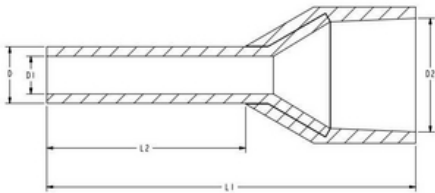

Covered Ferrule For 10 AWG.

## Features

- Made of electrolytic copper, tin plated
- Smooth funnel entry to make wire insertion easier
- Secure contacting even after multiple reconnections
- Long-term contact resistance
- No fraying of strands
- No breakage of wire strands when wire is bent, under stress, or in vibration environment
- RoHS Compliant

## Application

For Use On Copper Conductor

## General

Catalog Number	YF1010ITL
Connector Type	End Termination
EU RoHS Indicator	Yes
Insulation	Y
Material	Copper
Plated	Y
Plating Type	Tin - Electro Plated
Sub Brand	FERRULES
Type	Bootlace Ferrule
UPC	621945622937

## Dimensions

Dimension - D inch	0.15 in
Dimension - D1 inch	0.14 in

Dimension - D2 inch	0.25 in
Dimension - Length Overall inch	0.71 in

## Conductor Related

Conductor - Copper Solid Size	10 AWG
Conductor - Copper Str Size	10 AWG
Conductor Size	10 AWG

## Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance	CM
Status	
UL Listed	No

## Logistics

Carton Quantity	100
Minimum Pack Quantity	100

## Product Assets

[Catalogs - BURNDY Master Catalog - Section B - Small Terminals](#)  
[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)  
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)  
[Sales Drawings - 50111876](#)  
[Specifications - YF1010ITL](#)