


YF1/018UIL, Bare Ferrule For 1/0 AWG

By Burndy
Catalog # YF1/018UIL

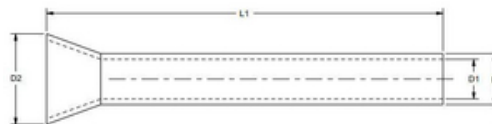

Bare Ferrule For 1/0 AWG.

Features

- Made of electrolytic copper, tin plated
- Seamless barrels
- Smooth funnel entry to make wire insertion easier
- UL listed per UL486F requirements
- RoHS Compliant

Application

For Use On Copper Conductor

General

Catalog Number	YF1/018UIL
Connector Type	End Termination
EU RoHS Indicator	Yes
Insulation	N
Material	Copper
Plated	Y
Plating Type	Tin - Electro Plated
Sub Brand	FERRULES
Type	Bootlace Ferrule
UPC	621945623408

Dimensions

Dimension - D inch	0.43 in
Dimension - D1 inch	0.41 in
Dimension - D2 inch	0.51 in
Dimension - Length Overall inch	0.71 in

Conductor Related

Conductor - Copper Solid Size	1/0 AWG
Conductor - Copper Str Size	1/0 AWG
Conductor Size	1/0 AWG

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - Industry Standards	UL486
Met	
Standards - RoHS Compliance	CM
Status	
UL Listed	Yes

Logistics

Carton Quantity	50
Minimum Pack Quantity	50

Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section B - Small Compression](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - 50111874](#)
- [Specifications - YF1/018UIL](#)