


# YF1210IDL, Covered Ferrule For 12 AWG

By Burndy  
Catalog # [YF1210IDL](#)

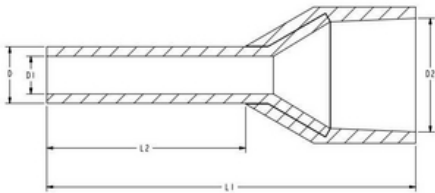

Covered Ferrule For 12 AWG.

## Features

- Made of electrolytic copper, tin plated
- Smooth funnel entry to make wire insertion easier
- Secure contacting even after multiple reconections
- Long-term contact resistance
- No fraying of strands
- No breakage of wire strands when wire is bent, under stress, or in vibration environment
- UL listed per UL486F requirements
- RoHS Compliant

## Application

For Use On Copper Conductor

## General

Catalog Number	YF1210IDL
Connector Type	End Termination
EU RoHS Indicator	Yes
Insulation	Y
Material	Copper
Plated	Y
Plating Type	Tin - Electro Plated
Sub Brand	FERRULES
Type	Bootlace Ferrule
UPC	621945622357

## Dimensions

Dimension - D inch	0.13 in
Dimension - D1 inch	0.11 in

Dimension - D2 inch	0.19 in
Dimension - Length Overall inch	0.67 in

## Conductor Related

Conductor - Copper Solid Size	12 AWG
Conductor - Copper Str Size	12 AWG
Conductor Size	12 AWG

## Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - Industry Standards	UL486
Met	
Standards - RoHS Compliance	CM
Status	
UL Listed	Yes

## Logistics

Carton Quantity	500
Minimum Pack Quantity	500

## Product Assets

[Catalogs - BURNDY Master Catalog - Section B - Small Terminals](#)  
[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)  
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)  
[Sales Drawings - 50111876](#)  
[Specifications - YF1210IDL](#)