

YFTW1212DL, Covered Twin Ferrule For 12 AWG

By Burndy
Catalog # [YFTW1212DL](#)

Covered Twin Ferrule For 12 AWG.

Features

- Made of electrolytic copper, tin plated
- Smooth funnel entry to make wire insertion easier
- Secure contacting even after multiple reconecctions
- Long-term contact resistance
- No fraying of strands
- No breakage of wire strands when wire is bent, under stress, or in vibration environment
- UL listed per UL486F requirements
- RoHS Compliant

Application


For Use On Copper Conductor

General

Catalog Number	YFTW1212DL
Connector Type	End Termination
EU RoHS Indicator	Yes
Insulation	Y
Material	Copper
Plated	Y
Plating Type	Tin - Electro Plated
Sub Brand	FERRULES
Type	Bootlace Ferrule
UPC	621945623118

Dimensions

Dimension - D inch	0.16 in
Dimension - D1 inch	0.15 in
Dimension - D2 inch	0.35 in

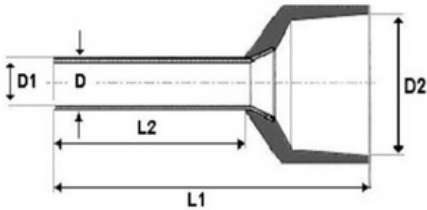

Dimension - Length Overall 0.91 in
inch

Conductor Related

Conductor - Copper Solid Size	12 AWG
Conductor - Copper Str Size	12 AWG
Conductor Size	12 AWG

Certifications And Compliance

Buy America(n) Qualified	TAA Compliant (All status valid till December 2024)
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - Industry Standards	UL486
Met	
Standards - RoHS Compliance	CM
Status	
UL Listed	Yes

Logistics

Carton Quantity	1
Minimum Pack Quantity	100

Product Assets

[Catalogs - BURNDY Master Catalog - Section B - Small Terminals](#)
[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Sales Drawings - 50111876](#)
[Specifications - YFTW1212DL](#)