




YGC6C8 Compression C-Crimp Connector, #6 AWG Run, #8 AWG Tap

By Burndy
Catalog # [YGC6C8](#)

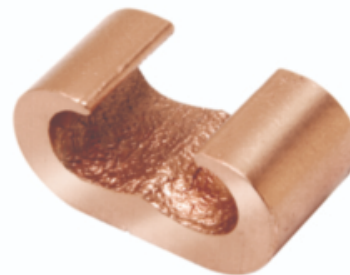

Copper Compression C Tap, 6 AWG(Run)/8 AWG(Tap).

General

Catalog Number	YGC6C8
Connector Type	Tap
Die Index	BG
Material	Copper
Physical Attribute - Number of Crimps Required	2
Plated	N
Plating Type	Unplated
Trade Name	CRIMPIT™
Type	Taps
UPC	781810102596
UPC 12 Digit	7818101025966

Dimensions

Dimension - Height fraction	46/63 in
Dimension - Height inch	0.73 in
Dimension - L Length Overall mm	16 mm
Dimension - Length Overall inch	0.62 in

Conductor Related

Conductor - Copper Solid Run Range	6 AWG
Conductor - Copper Solid Tap Range	8 AWG
Conductor - Copper Str Run Range	6 AWG
Conductor - Copper Str Tap Range	8 AWG

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Listed Direct Burial	Yes
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL467
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	100
Minimum Pack Quantity	1
Pallet Quantity	46400

Product Assets

[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Catalogs - BURNDY Master Catalog - Section E1 - Compression Grounding](#)
[Customer Notices - Prop 65 Notice](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Product Cross Section Image\(s\) - BUR_YGC_LineArt](#)
[Sales Drawings - SD..209501-01](#)
[Specifications - YGC6C8](#)