




YGC8C8 Compression C-Crimp Connector, #8 Sol/Str Run, #8 Sol/Str Tap

By Burndy
Catalog # YGC8C8

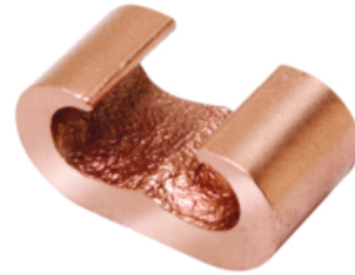

COPPER CRIMPIT™ Compression C Connector, .52 in L, #8 Sol. #8 Str. (Run) , #8 Sol. #8 Str. (Tap).

Application

For Direct Burial In Earth Or Concrete

General

Connector Type	Tap
Die Index	162
EU RoHS Indicator	Yes
Material	Copper
Physical Attribute - Number of Crimps Required	2
Plated	N
Plating Type	Unplated
Sub Brand	HYGROUND, CRIMPIT
Trade Name	CRIMPIT™
Type	Taps
UPC	781810102558
UPC 12 Digit	7818101025588

Dimensions

Dimension - Height fraction	23/50 in
Dimension - Height inch	0.46 in
Dimension - L Length Overall mm	13 mm
Dimension - Length Overall inch	0.52 in

Conductor Related

Conductor - Copper Solid Run	8 AWG
Conductor - Copper Solid Run Range	8 AWG
Conductor - Copper Solid Tap	8 AWG
Conductor - Copper Solid Tap Range	8 AWG
Conductor - Copper Str Run	8 AWG
Conductor - Copper Str Run Range	8 AWG
Conductor - Copper Str Tap	8 AWG
Conductor - Copper Str Tap Range	8 AWG

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Listed Direct Burial	Yes
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL467
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	100
Minimum Pack Quantity	1
Pallet Quantity	46400

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Product Cross Section Image\(s\) - BUR_YGC_LineArt](#)
[Sales Drawings - SD209501-01](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY-YGC8C8-SPEC-EN | REV 5/2024

