




## YGHA2CN Compression Grounding Lug, 2 AWG Cu, 1-Hole, 1/2" Stud

By Burndy  
Catalog # [YGHA2CN](#)

HYLUG™ Copper Compression Terminal for Grounding; Heavy Duty; 1-Hole.

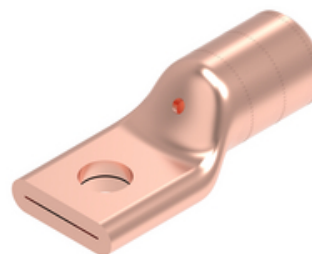

\*Representative Image

### General

Catalog Number	YGHA2CN
Connector Type	Terminal
Die Index	11
Material	Copper
Physical Attribute - Number of Crimps Required	1
Plated	N
Plating Type	Unplated
Trade Name	HYLUG™
Type	Terminals
UPC	781810185933
UPC 12 Digit	7818101859333

### Dimensions

Dimension - B Length fraction	3/4 in
Dimension - B Length inch	0.75 in
Dimension - D inch	1.27 in
Dimension - Hole Size inch	0.56 in
Dimension - Hole Size mm	14 mm
Dimension - L Length Overall mm	62 mm
Dimension - Length Overall inch	2.46 in
Dimension - N inch	0.63 in
Dimension - Outside Diameter inch	0.50 in
Dimension - Pad Width inch	0.97 in
Dimension - Z (inch)	0.64 in
Physical Attribute - Tongue Angle	Straight

### Conductor Related

Conductor - Copper Str Size	2 AWG
Conductor - Copper Str Size Range	2 AWG
Conductor Type	<ul style="list-style-type: none"><li>• CU C Str-Size</li><li>• CU C Solid-Size</li></ul>

### Certifications And Compliance

Certification - CSA Approved	Yes
Certification - UL Listed Direct Burial	Yes
Standards - Industry Standards Met	UL467;UL468A-468B;IEEE 837
Standards - RoHS Compliance Status	CM

### Logistics

Carton Quantity	100
Minimum Pack Quantity	1
Pallet Quantity	14800

### Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - SD..211241-01](#)
- [Specifications - YGHA2CN](#)