




YGHC26C26TN Compression Grounding C-TAP Connector

By Burndy
Catalog # [YGHC26C26TN](#)

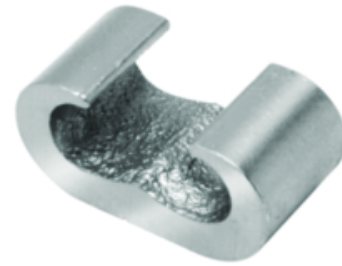

Cu Compression Ground Tap Connector, 1 str to 2/0 str, 3/8 " Rod (Run), 1 str to 2/0 str (Tap), Tin Plated.

General

Connector Type	Tap
Die Index	O
Material	Copper
Physical Attribute - Number of Crimps Required	1
Plated	Y
Plating Type	Tin - Electro Plated
Trade Name	HYTAP™
Type	Taps
UPC	781810171608
UPC 12 Digit	7818101716088

Dimensions

Dimension - Height fraction	1-27/50 in
Dimension - Height inch	1.54 in
Dimension - L Length Overall mm	19 mm
Dimension - Length Overall inch	0.75 in

Conductor Related

Conductor - Copper Str Run	1 AWG;1/0 ;2/0 AWG
Conductor - Copper Str Run Range	1 AWG-2/0 AWG
Conductor - Copper Str Tap	1 AWG;1/0 ;2/0 AWG
Conductor - Copper Str Tap Range	1-2/0
Conductor - Rod Run	3/8 in
Conductor - Rod Run Range	3/8 in

Certifications and Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Listed Direct Burial	Yes
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	Direct Burial
Standards - Industry Standards Met	<ul style="list-style-type: none">• UL467• IEEE 837• UL468A-468B
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	25
Minimum Pack Quantity	1
Pallet Quantity	14850

Product Assets

[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - SD086223-01](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRDY-YGHC26C26TN-SPEC-EN | REV 8/2023