




# YGHC29C29 Compression Grounding C-TAP Connector

By Burndy  
Catalog # YGHC29C29

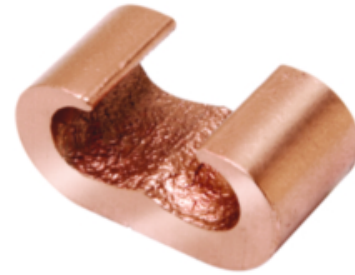

Copper Compression C Connector, 3/0 AWG(Str) - 250 kcmil, 1/2" or 5/8" Rod (Run) & 3/0 AWG(Str) - 250 kcmil (Tap).

## Application

For Direct Burial Cables

## General

Connector Type	Tap
Die Index	997
EU RoHS Indicator	Yes
Material	Copper
Physical Attribute - Number of Crimps Required	1
Plated	N
Plating Type	Unplated
Sub Brand	HYGROUND, HYTAP
Trade Name	HYTAP™
Type	Taps
UPC	781810221051
UPC 12 Digit	7818102210511

## Dimensions

Dimension - B Length inch	0.88 in
Dimension - Height fraction	2-3/50 in
Dimension - Height inch	2.06 in
Dimension - L Length Overall mm	22 mm
Dimension - Length Overall inch	0.88 in

## Conductor Related

Conductor - Copper Str Run	3/0 AWG;4/0 AWG;250 kcmil
Conductor - Copper Str Run Range	3/0 AWG-250 kcmil
Conductor - Copper Str Tap	3/0 AWG;4/0 AWG;250 kcmil
Conductor - Copper Str Tap Range	3/0 AWG-250 kcmil
Conductor - Rod Run	1/2 in;5/8 in
Conductor - Rod Run Range	1/2 in-5/8 in

## Certifications and Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Listed Direct Burial	Yes
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	Direct Burial
Standards - Industry Standards Met	UL467;IEEE 837;UL468A-468B
Standards - RoHS Compliance Status	CM
UL Listed	Yes

## Logistics

Carton Quantity	25
Minimum Pack Quantity	1
Pallet Quantity	7400

## Product Assets

[3D Models - YGHC29C29\\_MODEL-PDF](#)  
[3D Models - YGHC29C29\\_MODEL-STEP](#)  
[3D Models - YGHC29C29\\_MODEL-IGES](#)  
[Catalogs - Full Line BURNDY Catalog](#)  
[Customer Notices - Prop 65 Notice](#)  
[Sales Drawings - SD086223-01](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
BRDY-YGHC29C29-SPEC-EN | REV 8/2023