


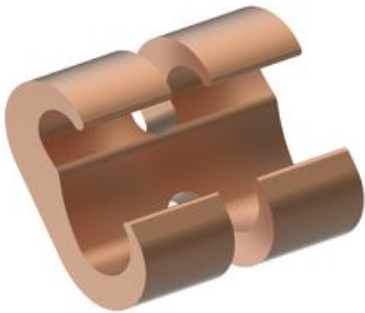

YGHHC26C26 Compression Grounding C-TAP Connector

By Burndy
Catalog # [YGHHC26C26](#)

HYTAP™ Connector, Compression Ground, Cable Range: 1 STR - 2/O STR (RUN), 1 STR - 2/O STR (TAP), Height: 1.54 in, Length: 0.75 in, Z: 1.88 in



Application

Cable to Cable or Cable to Ground Rod Applications

General

Connector Type	Tap
Construction Material - Main	Copper
Die Index	O
EU RoHS Indicator	Contact Manufacturer
Material	Copper
Plated	N
Sub Brand	Connector
Trade Name	HYTAP™
Type	Taps
UPC	621945456228
UPC 12 Digit	6219454562288

Dimensions

Dimension - Height inch	1.54
Dimension - Width inch	1.88
Height	1.54 in
Width	1.88 in

Conductor Related

Conductor - Copper Str Run Range	1 Stranded - 2/O Stranded
Conductor - Copper Str Tap Range	1 Stranded - 2/O Stranded
Conductor - Rod Run Range	3/8" Rod
Conductor - Rod Size Range	3/8" Rod
Conductor - Rod Tap Range	3/8" Rod

Certifications And Compliance

Certification - CSA Approved	[Delete]
Certification - UL Listed Direct Burial	Yes
Industry Standard(s)	<ul style="list-style-type: none">UL 467IEEE 837IEEE 837 2014 QualifiedUL 486A-486B
Standards - Industry Standards Met	UL467;IEEE 837;IEEE 837 2014 Qualified;UL 486A-486B
Standards - RoHS Compliance Status	CM

Logistics

Carton Quantity	30
Minimum Pack Quantity	1
Pallet Quantity	7200

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - 50064429](#)



A proud member of the Hubbell Family.