




# YGHHC26C26 Compression Grounding C-TAP Connector

By Burndy  
Catalog # [YGHHC26C26](#)

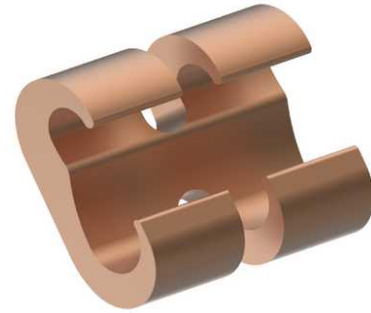

HYTAP™ Connector, Compression Ground, Cable Range: 1 STR - 2/0 STR (RUN), 1 STR - 2/0 STR (TAP), Height: 1.54 in, Length: 0.75 in, Z: 1.88 in

## Application

Cable to Cable or Cable to Ground Rod Applications

## General

Connector Type	Tap
Construction Material - Main	Copper
Die Index	O
EU RoHS Indicator	Contact Manufacturer
Material	Copper
Plated	N
Sub Brand	Connector
Trade Name	HYTAP™
Type	Taps
UPC	621945456228
UPC 12 Digit	6219454562288

## Dimensions

Dimension - Height inch	1.54
Dimension - Width inch	1.88
Height	1.54 in
Width	1.88 in

## Conductor Related

Conductor - Copper Str Run Range	1 Stranded - 2/0 Stranded
Conductor - Copper Str Tap Range	1 Stranded - 2/0 Stranded
Conductor - Rod Run Range	3/8" Rod
Conductor - Rod Size Range	3/8" Rod
Conductor - Rod Tap Range	3/8" Rod

## Certifications and Compliance

Certification - CSA Approved	[Delete]
Certification - UL Listed Direct Burial	Yes
Industry Standard(s)	<ul style="list-style-type: none"><li>UL 467</li><li>IEEE 837</li><li>IEEE 837 2014 Qualified</li><li>UL 486A-486B</li></ul>
Standards - Industry Standards Met	UL467;IEEE 837;IEEE 837 2014 Qualified;UL 486A-486B
Standards - RoHS Compliance Status	CM

## Logistics

Carton Quantity	30
Minimum Pack Quantity	1
Pallet Quantity	7200

## Product Assets

[Catalogs - Full Line BURNDY Catalog](#)  
[Customer Notices - Prop 65 Notice](#)  
[Sales Drawings - 50064429](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
BRDY-YGHHC26C26-SPEC-EN | REV 8/2023