




YGHHC34C29 Compression Grounding C-TAP Connector

By Burndy
Catalog # [YGHHC34C29](#)

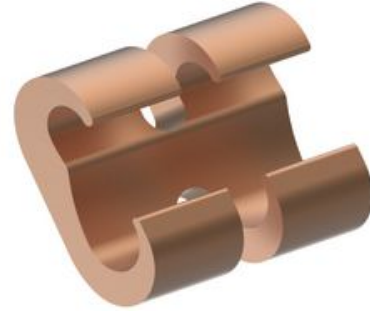

Compression ground connector, Material: Copper, Range Run: 300 Kcmil-500 Kcmil, Tap: 3/0 Str-250 Kcmil.

Application

For Direct Burial cables

General

Connector Type	Tap
Die Index	1011
EU RoHS Indicator	Contact Manufacturer
Material	Copper
Plated	N
Sub Brand	HYTAP
Trade Name	HYTAP™
Type	Taps
UPC	621945456266
UPC 12 Digit	6219454562666

Dimensions

Width	2.13 in
-------	---------

Conductor Related

Conductor - Copper Str Run Range	300 - 500 kcmil
Conductor - Copper Str Tap Range	3/0 Stranded - 250 kcmil

Certifications And Compliance

Certification - CSA Approved	[Delete]
Certification - UL Listed Direct Burial	Yes
Industry Standard(s)	<ul style="list-style-type: none">UL 467IEEE 837IEEE 837 2014 QualifiedUL 486A-486B
Standards - Industry Standards Met	UL467;IEEE 837;IEEE 837 2014 Qualified;UL 486A-486B
Standards - RoHS Compliance Status	CM

Logistics

Carton Quantity	10
Minimum Pack Quantity	1
Pallet Quantity	2400

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - 50064429](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY-YGHHC34C29-SPEC-EN | REV 5/2024