




YGHHC34C34 Compression Grounding C-TAP Connector

By Burndy
Catalog # [YGHHC34C34](#)

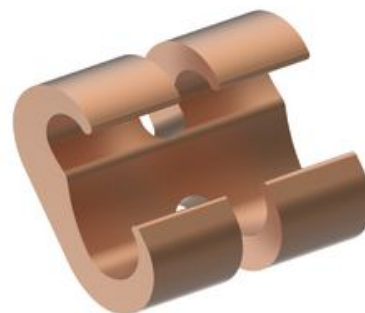

Compression ground connector, Material: Copper, Range Run & Tap: 300 Kcmil-500 Kcmil

Application

Cable to Cable or Cable to Ground Rod Applications

General

Catalog Number	YGHHC34C34
Connector Type	Tap
Construction Material - Main	Copper
Die Index	1011
EU RoHS Indicator	Contact Manufacturer
Material	Copper
Plated	N
Sub Brand	Connector
Trade Name	HYTAP™
Type	Taps
UPC	621945456273
UPC 12 Digit	6219454562733

Dimensions

Width	2.91 in
-------	---------

Conductor Related

Conductor - Copper Str Run Range	300 - 500 kcmil
Conductor - Copper Str Tap Range	300 - 500 kcmil

Certifications And Compliance

Buy American Compliant	No
Certification - CSA Approved	[Delete]
Certification - UL Listed Direct Burial	Yes
Industry Standard(s)	<ul style="list-style-type: none"> • UL 467 • IEEE 837 • IEEE 837 2014 Qualified • UL 486A-486B
Standards - Industry Standards Met	UL467;IEEE 837;IEEE 837 2014 Qualified;UL 486A-486B
Standards - RoHS Compliance Status	CM

Logistics

Carton Quantity	10
Minimum Pack Quantity	1
Pallet Quantity	1500

Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section E1 - Compression Grounding](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - 50064429](#)
- [Specifications - YGHHC34C34](#)