




# YGHP29C2MX Figure 6 Compression Grounding Connector

By Burndy  
Catalog # [YGHP29C2MX](#)

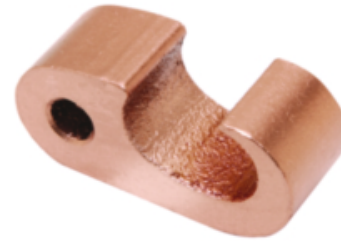

COMP-SPLICE-W/O BAG-PENA.

## General

Connector Type	Tap
Die Index	997
Material	Copper
Plated	N
Plating Type	Unplated
Type	Taps
UPC	781810308707
UPC 12 Digit	7818103087077

## Dimensions

Dimension - B Length fraction	1/3 in
Dimension - B Length inch	0.33 in
Dimension - D inch	0.43 in
Dimension - Length Overall inch	2.09 in
Dimension - Pad Width inch	0.43 in
Dimension - Width fraction	3/4 in
Dimension - Width inch	0.75 in

## Conductor Related

Conductor - Copper Str Size A	1/0 ;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil
Conductor - Copper Str Size A Range	1/0 -250 kcmil
Conductor - Copper Str Size B	5 AWG;4 AWG;3 AWG;2 AWG
Conductor - Copper Str Size B Range	5 AWG-2 AWG

## Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Listed Direct Burial	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

## Logistics

Carton Quantity	100
Minimum Pack Quantity	1
Pallet Quantity	6000

## Product Assets

[Catalogs - Full Line BURNDY Catalog](#)  
[Customer Notices - Prop 65 Notice](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.  
BRDY-YGHP29C2MX-SPEC-EN | REV 5/2024